


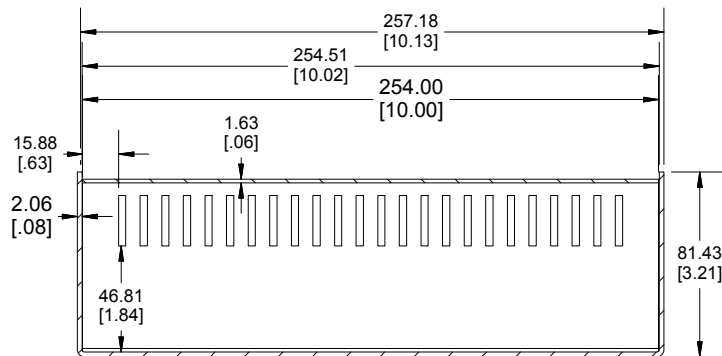


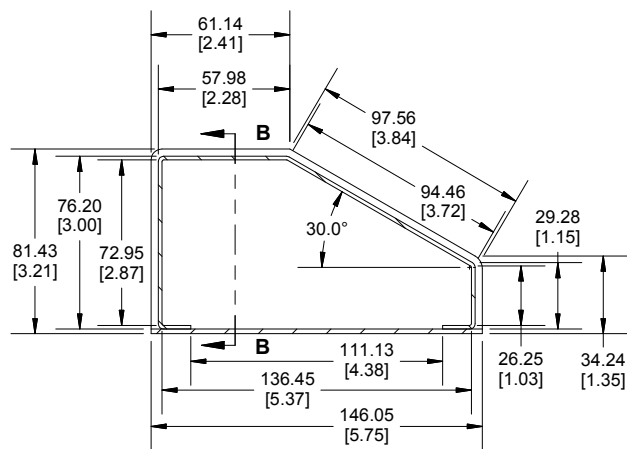


SECTION B-B

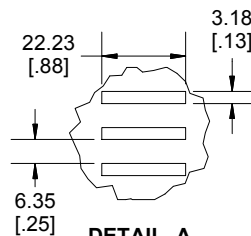

DETAIL A

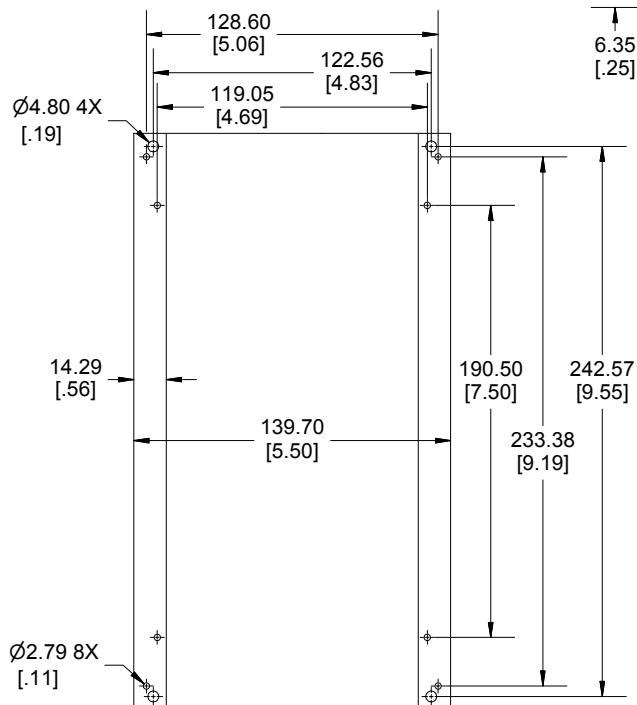


TOP PANEL - BOTTOM ENCLOSURE

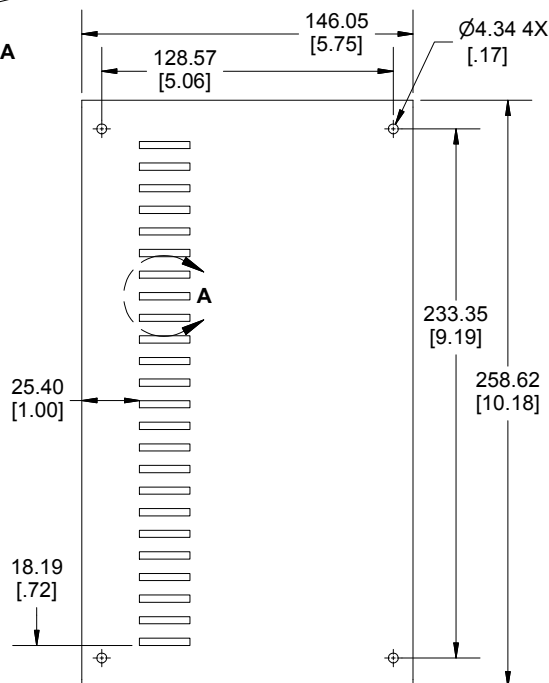

ENCLOSURE CASE - BOTTOM VIEW

Dimensions:
mm
[inches]

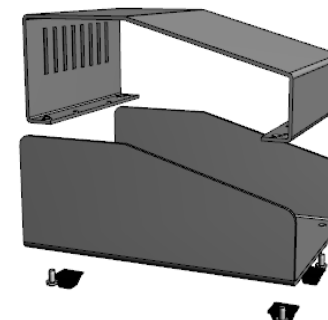

Enclosures can be Factory Modified (Milling, Drilling, Printing etc.)
Contact Factory mjm@hammondmg.com for quotes
Solid models of this enclosure available in STEP or IGES.
(Part number and text placement/orientation on our products are subject to change,
we do not recommend using them as a locating reference for modification purposes)

NOTE

Purchased assembly includes case, cover, 4 cover screws, and 4 rubber feet.
Case made from 12 Gauge aluminum (.081"), Top made from 14 Gauge aluminum (.064").

Recommended screw torque 150-175 cN-m (13.3-15.5 lbf-in)

1456

1456KE3 Regular Enclosure

Beige Top / Blue Case	1456KE3WHBU
Black Top / Blue Case	1456KE3BKBU
Black Top / Black Case	1456KE3BKBK

ACCESSORIES

Natural Finish Cover Screws (Pkg 6) [6-32 x 1/4" Self-Tapping Screws]	1421J6
Black Cover Screws (Pkg 6) [6-32 x 1/4" Self-Tapping Screws]	1421J6BK
Rubber Feet [0.5 x 0.5" Self-adhesive] (Pkg 24)	1421T3

HAMMOND
MANUFACTURING
1456KE3
www.hammondmg.com