
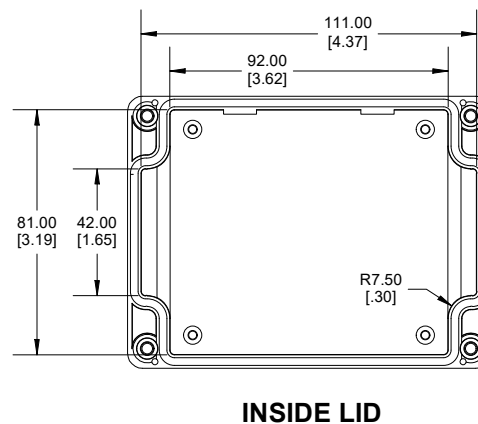
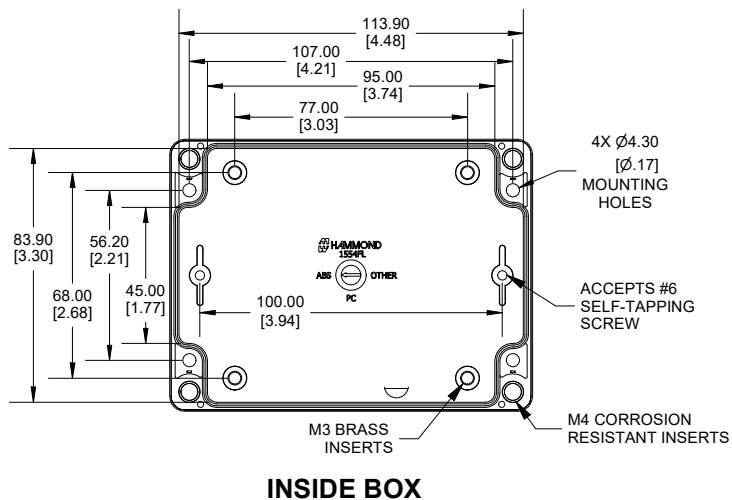
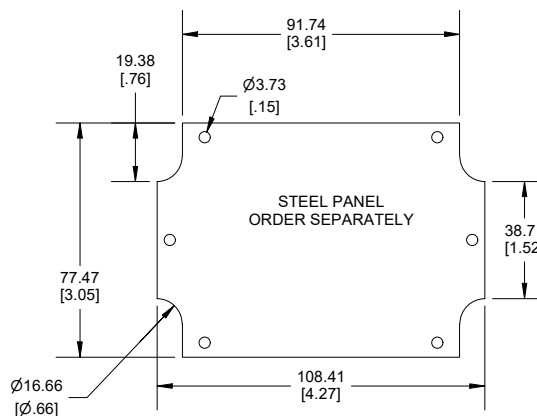
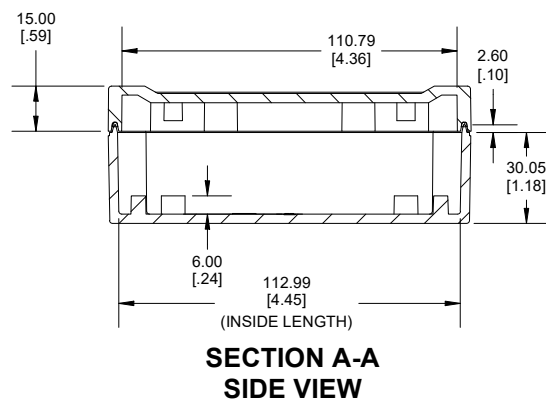
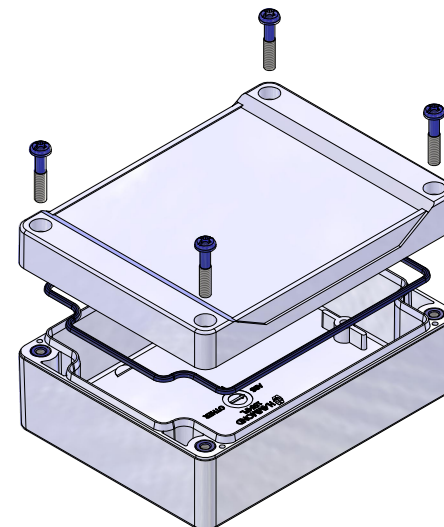
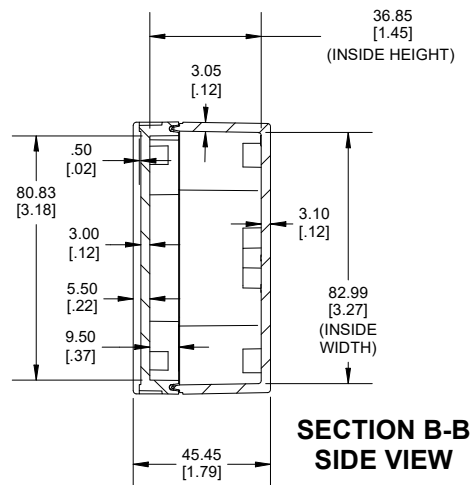


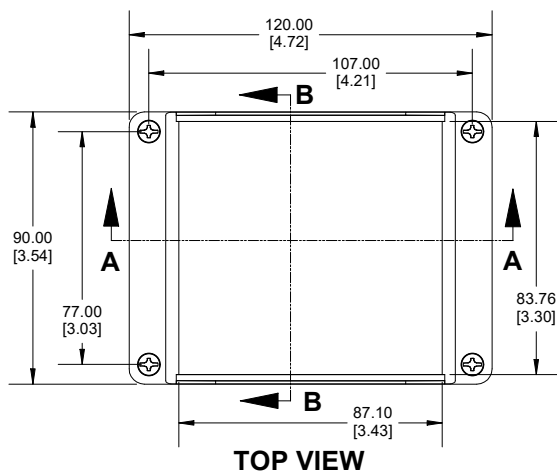

Dimensions:
mm
[inches]

POLYCARBONATE
VERSION ONLY
UL US LISTED
FILE #E65324
TYPE 4,4X,6,6P

Enclosures can be Factory Modified (Milling, Drilling, Printing etc.)
Contact Factory (modshop@hammfg.com) for quotes
Solid models of this enclosure available in .stp or .x_t
(Part number and text placement/orientation on our products are subject to change,
we do not recommend using them as a locating reference for modification purposes)

NOTE

Purchased assembly includes box, styled lid, 4 cover screws, and preformed silicone gasket.

General Purpose ABS version is not UL approved. (Matl UL94 - HB)

Polycarbonate version is UL 508A approved. (Matl UL94 - 5VA @ 3mm)

Recommended Cover screw torque -- 43-57 ozf-in (30-40 cN-m)

1555FL

1555FL Regular Enclosure

General Purpose ABS RAL-7035

1555FLGY

Polycarbonate RAL-7035

1555FL2GY

ACCESSORIES

Steel Inner Panels

1554FPL

Steel Panel / P.C. Board Screw
[M3-0.5 x 8mm Plated] (Pkg 100)

1591MM100

Steel Panel / P.C. Board Self Tapping Screw
[#6 X 1/4" (6.4mm) Plated] (Pkg 100)

1598ATS100

Stainless Steel Cover Screws
[M4-0.7 X 20mm] (Pkg 50)

SC576-50

Silicone Pre-formed Gasket Black (Pkg 2)

1554FGASKET



HAMMOND

1555FL

www.hammondmfg.com