

VOLTCRAFT

VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For decades, our product range has been dynamically adapting to the constant changes in the industry.

We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.

MSL-820 (PVC Test Leads)

MSL-850 (Silicon Test Leads)

TEST LEAD SET WITH GOLD PLATED TEST TIPS




Item no. 3462537 (MSL-820) / 3462538 (MSL-850)

FEATURES

CAT III 1000V // CAT IV 600V // 10 A // Gold plated // 4 mm connectors // 1.2 m test leads

DIMENSIONS

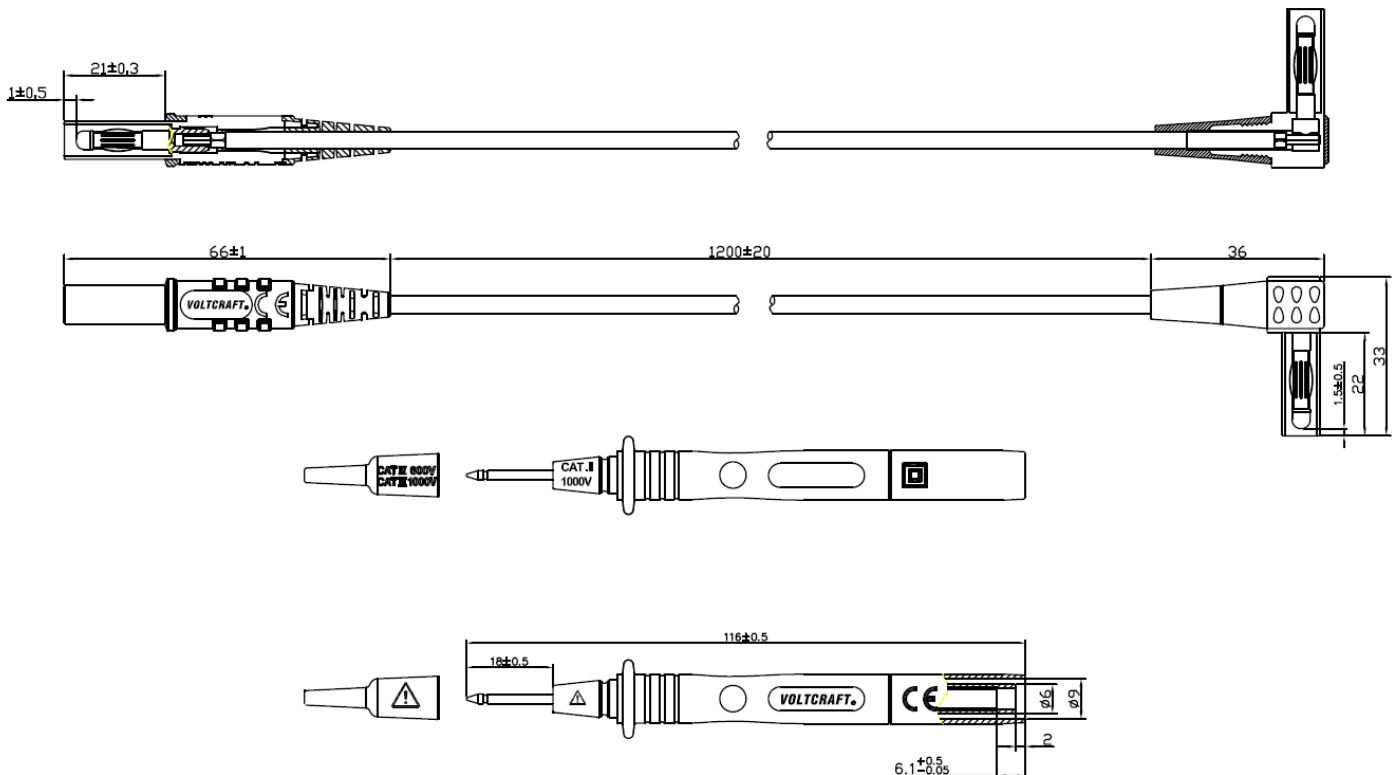

All measurements in mm

TECHNICAL DATA

Test leads

Item	Value
Overvoltage category	1000 V CAT III 600 V CAT IV
Rated current	max. 10 A
Connector	4 mm
Conductor cross-section	18 AWG 0,823 mm²
Colour	Red, black
Insulated material	PA
Material	Cable: PVC (MSL-820) Plug: PP+TPE (MSL-850)
Working temperature and humidity	-5 to +45 °C / <85 % RH
Storage temperature and humidity	-10 to +50 °C / <85 % RH
Cable length	1.2 m

Test probes

Item	Value
Overvoltage category	1000 V CAT III 600 V CAT IV
Rated current	max. 10 A
Connector	4 mm
Colour	Red, black
Working temperature and humidity	-10 to +50 °C / < 80 % RH
Storage temperature and humidity	-10 to +55 °C / < 80 % RH
Length	116 mm

PACKAGE CONTENTS

- 1x Test leads pair
- 1x Test probe pair

