

Datasheet – TRU Components


Item no.: 3465761 - 3465768



Hose connector PB and PEG series

PB Series


- Max. operating pressure: 10 bar
- Min. operating pressure: -1 bar
- Operating temperature: -10 up to 80 °C

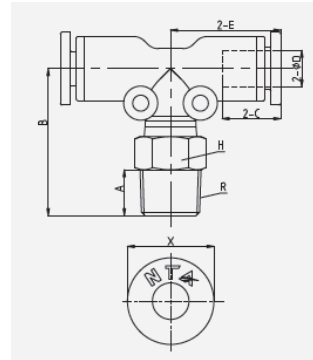

Item No.	D	R	A	E	B	H	X	C
3465761	4	M5	3.5	18	21.8	8	9.9	15.3
3465762	6	M5	3.5	20.3	23.8	8	11.8	16.7
3465763	4	G1/8	7.5	18	24.3	10	9.9	15.3
3465764	6	G1/8	7.5	20.3	26.8	12	11.8	16.7

PEG Series

- Max. operating pressure: 10 bar
- Min. operating pressure: -1 bar
- Operating temperature: -10 up to 80 °C

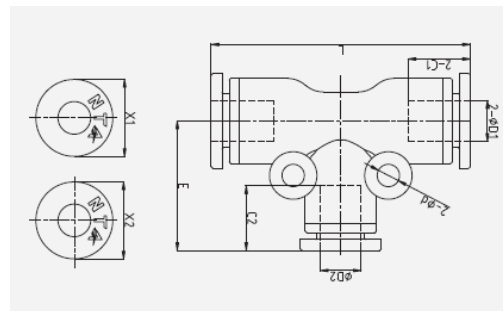

Item No.	D1	D2	E	L	d	C1	C2	X1	X2
3465765	6	4	20	40.5	3.2	16.7	15.3	11.8	9.9
3465766	8	6	23	47	3.3	19.1	16.7	13.8	11.8
3465767	10	8	26.8	53.6	4.3	21.2	19.1	16.8	13.8
3465768	12	10	30	61.6	4.3	24.4	21.2	19.8	16.8