




4-Port USB KVM Switch

TK-407K (v2.0R)


- Control up to 4 computers/servers with one set of console devices
- USB keyboard/mouse emulation with 4 sets of detachable KVM cables
- High video quality, up to 2048 x 1536 VGA resolution
- Compliant with Windows®, Linux, and Mac OS™
- Auto-Scan and LED display for computer monitoring
- Keyboard status restored when switching between computers
- Computer selection by top panel push buttons, keyboard hot key commands, or Windows-based client switching software*
- User definable hot key (Windows only)
- Plug & Play, and hot-pluggable
- USB interface power method
- All required cabling included

TRENDnet's 4-Port USB KVM Switch, model TK-407K, lets you manage four PCs with just one set of keyboard, mouse, and monitor. This compact USB KVM switch is designed for VGA systems with USB mouse and keyboard connections. No driver installation required, simply plug in the devices to control four computers. Convenient top panel push buttons allow you to easily switch between different computers. Separate sets of KVM cables are included with the USB KVM Switch; users can start controlling four PCs instantly. The included KVM cables also provide power to the USB KVM Switch, eliminating the need for a power adapter. Hot Key operations provide immediate access to KVM features, such as computer switching, and auto-scanning.

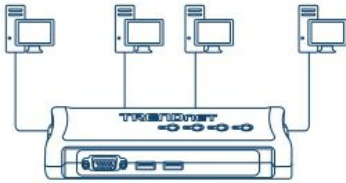

Computers

Conveniently control up to four PCs with just one set of USB mouse/keyboard, and VGA monitor.

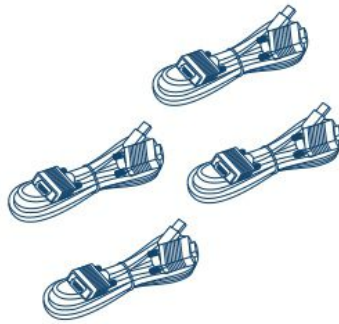

Included KVM Cables


KVM cable sets are included with the USB KVM Switch, allowing users to control four PCs immediately.



VGA Port

Supports high video quality VGA resolutions, up to 2048 x 1536 with a 60Hz refresh rate.

NETWORKING SOLUTION

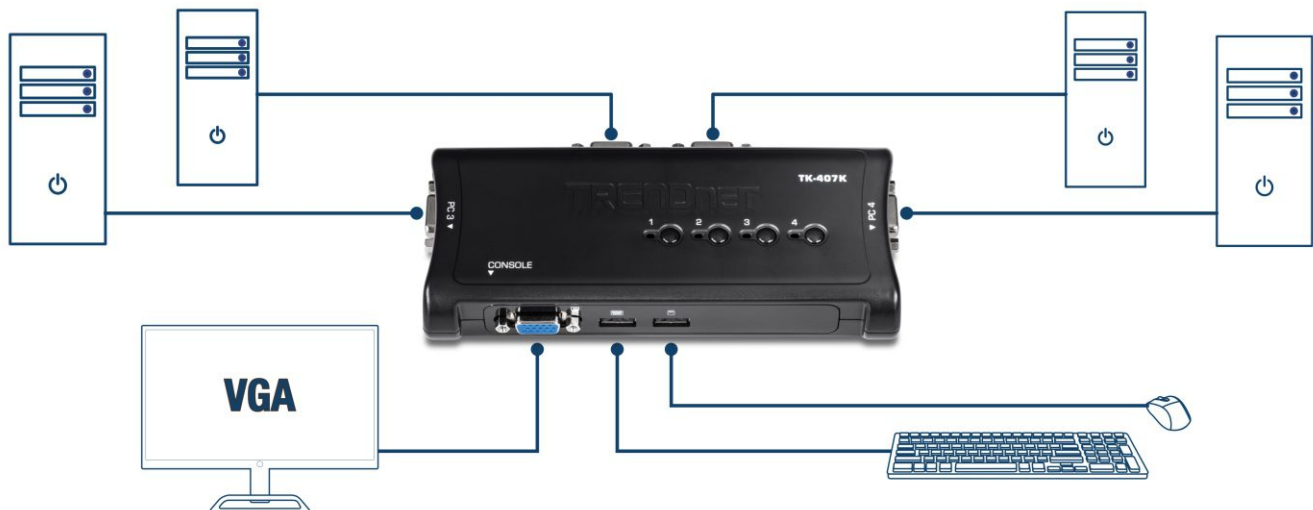

FEATURES



Computers

Control up to four PCs with just one set of USB mouse/keyboard, and VGA monitor



Included KVM Cables

Separate sets of KVM cables are included with the USB KVM Switch, so users can start controlling four PCs instantly



VGA Port

Supports high video quality VGA resolutions, up to 2048 x 1536 with a 60Hz refresh rate



USB Mouse & Keyboard

USB emulation technology supports most keyboard and mouse designs



Hot Keys

Hot Key operations provide immediate access to USB KVM features, such as computer switching, and auto-scanning




Multiple Platform Compatibility

The USB KVM Switch is compatible with Windows, Mac, and Linux operating systems



Computer Ports

Requires free USB and VGA ports from connected computers

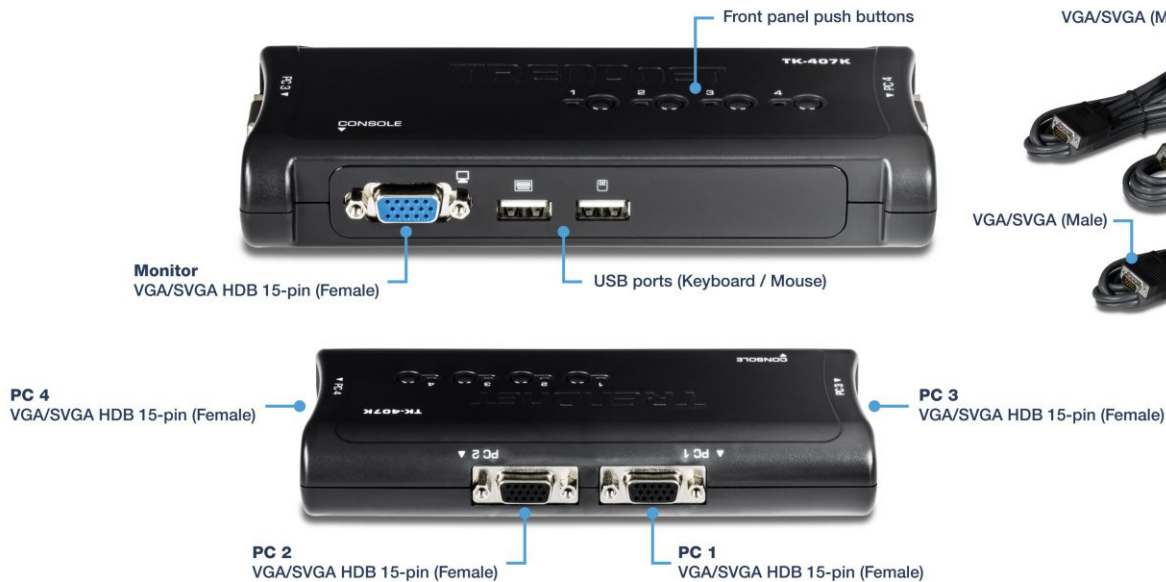

SPECIFICATIONS

Console Port Connectors

- 1 x VGA /SVGA HDB 15-pin (Female)
- 2 x USB ports (Keyboard / Mouse)

Computer Interface (up to 4)

- 1 x USB Type A
- 1 x VGA /SVGA HDB 15-pin (Female)

Cables (4 sets)

- 2 sets: 1.2m (4 ft.)
- 2 sets: 1.8m (6 ft.)
- VGA /SVGA (Male) to VGA /SVGA (Male) / USB Type A

Monitor Resolution

- 2048 x 1536 @ 60Hz

Switching Control

- Front panel push buttons
- Keyboard hot key commands
- Auto-Scan interval: 10 secs

Operating Temperature

- 0° – 40° C (32° – 104° F)

Operating Humidity

- Max. 90% non-condensing

Power

- USB powered
- Max. consumption: 0.7W

Dimensions

- 167 x 80 x 28mm (6.6 x 3.2 x 1.1 in.)

Weight

- 159g (5.6 oz.)

Warranty

- 2 year

Certifications

- CE
- FCC

Package Contents

- TK-407K
- Quick Installation Guide
- 2 x KVM Cables (1.2m/4 ft.)
- 2 x KVM Cables (1.8m/6 ft.)

All references to speed are for comparison purposes only. Product specifications, size, and shape are subject to change without notice, and actual product appearance may differ from that depicted herein.