



4-Port USB KVM Switch with Audio

TK-409K (v2.0R)


- Control up to 4 computers with one set of console devices
- 3.5mm speaker and microphone connections
- Designed for use with VGA systems
- High video quality, up to 2048 x 1536 VGA resolution
- Compliant with Windows, Linux, and Mac OS
- Auto-Scan and LED display for computer monitoring
- Keyboard status restored when switching between computers
- User definable hot key (Windows only)
- Plug & Play and hot-pluggable
- USB interface power method
- All required cables included
- No CD installation required

TRENDnet's 4-Port USB KVM Switch with Audio, model TK-409K, allows you to control four computers with one set of console controls. Experience up to 2048 x 1536 resolutions, no driver installation required. Separate sets of KVM cables are included with the KVM switch, so users can start controlling four workstations instantly. The KVM cables also provide power to the KVM switch, eliminating the need for a power adapter. Hot Key operations provide immediate access to features, such as computer switching, and auto-scanning. With its Hot-Plug and Audible Feedback, the 4-Port USB KVM Switch is the perfect choice for managing multiple PCs.




VGA Resolution

The VGA KVM Switch is designed for VGA systems with resolutions up to 2048 x 1536.

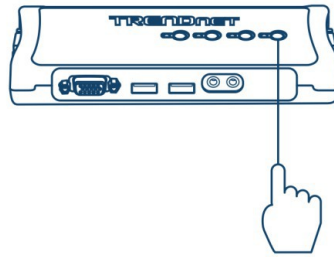

Push Button Selection


Conveniently use the integrated push buttons to easily switch between connected computers.

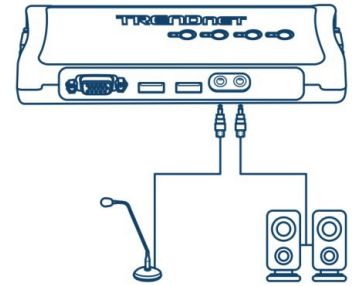

Audio Support

Full audio support through the 3.5mm microphone and speaker jacks maximize workstation productivity.

NETWORKING SOLUTION

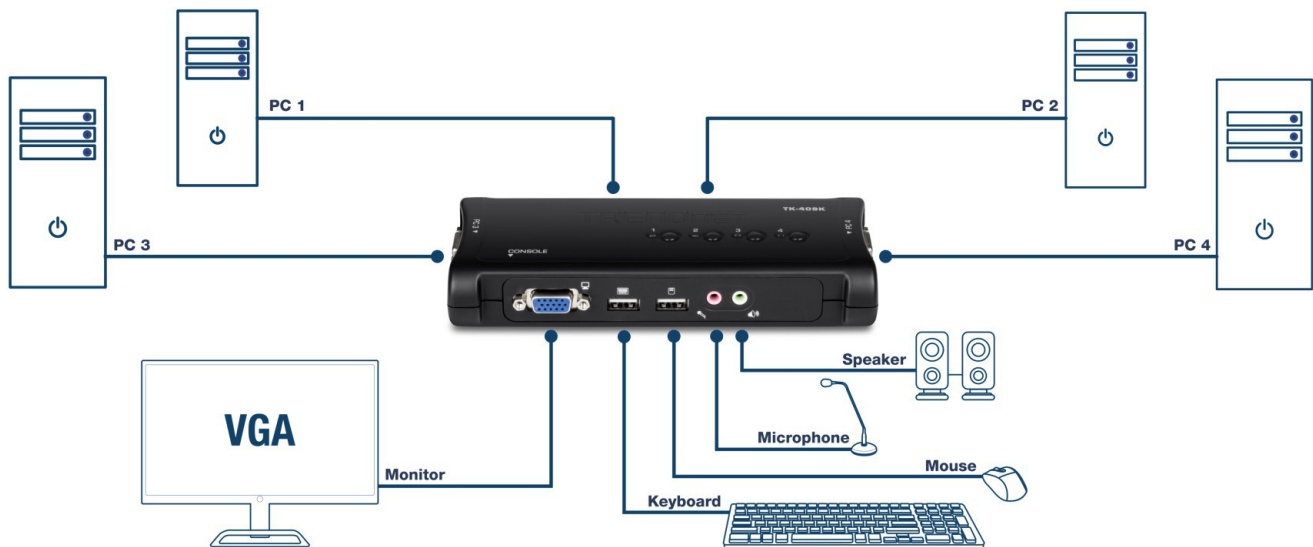

FEATURES



Computers

Control up to 4 computers with one set of console devices



Video Resolution

Supports resolutions up to 2048 x 1536



Push Button Controls

Use the front panel push buttons to switch between computers on the KVM switch



Audio Support

Full audio support through 3.5mm microphone and speaker jacks maximizes work station productivity



USB Mouse & Keyboard

Supports most wired keyboard and USB mouse designs



VGA

Designed to connect to VGA systems



Hot Keys

Hot Key command shortcuts for switching between computers



Included Cables

Includes four sets of KVM cables



Computer Ports


Requires free USB and VGA ports from connected computers



Compatibility


Compliant with Windows, Linux, and Mac OS

Front

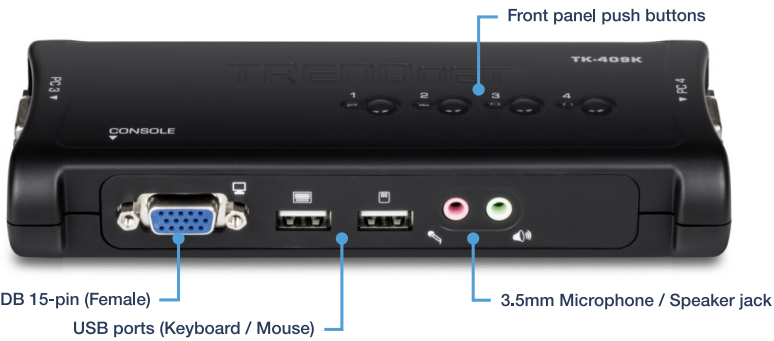

Back

PC 4
VGA/SVGA
HDB 15-pin (Female)

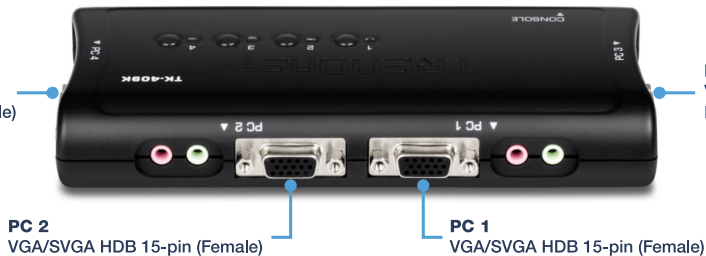

PC 3
VGA/SVGA
HDB 15-pin (Female)

PC 2
VGA/SVGA HDB 15-pin (Female)

PC 1
VGA/SVGA HDB 15-pin (Female)



SPECIFICATIONS

Console Port Connectors

- 1 x VGA /SVGA HDB 15-pin (Female)
- 2 x USB ports (Keyboard / Mouse)
- 1 x 3.5mm speaker jack
- 1 x 3.5mm microphone jack

Computer Interface (up to 4)

- 1 x USB Type A
- 1 x VGA /SVGA HDB 15-pin (Female)
- 1 x 3.5mm speaker jack
- 1 x 3.5mm microphone jack

Cables (4 sets)

- 2 sets: 1.2m (4 ft.)
- 2 sets: 1.8m (6 ft.)
- VGA /SVGA (Male) to VGA /SVGA (Male) / USB Type A
- Audio cables

Monitor Resolution

- 2048 x 1536 @ 60Hz

Switching Control

- Front panel push buttons
- Keyboard hot key commands
- Auto-Scan interval: 10 ~ 60 secs

Operating Temperature

- 0° – 40° C (32° – 104° F)

Operating Humidity

- Max. 90% non-condensing

Power

- USB powered
- Max. consumption: 0.7W

Dimensions

- 167 x 80 x 28mm (6.6 x 3.2 x 1.1 in.)

Weight

- 185g (6.5 oz.)

Certifications

- CE
- FCC

Warranty

- 2 year

Package Contents

- TK-409K
- Quick Installation Guide
- 2 x KVM and Audio cables (1.2m/4 ft.)
- 2 x KVM and Audio cables (1.8m/6 ft.)

All references to speed are for comparison purposes only. Product specifications, size, and shape are subject to change without notice, and actual product appearance may differ from that depicted herein.