



8-Port Rack Mount KVM Switch

TK-803R (v1.1R)

The 8-Port USB KVM Switch lets you manage multiple computers with just one set of keyboard, monitor and mouse. This rack mount device supports USB and PS/2 interface on the console side and USB only on the PC side. Popular hardware platforms such as PC, Linux and Mac are supported. Users can switch between PCs using hot-key or push button for flexible management. Users can also hot-plug PCs on the fly to avoid downtime. The 8-Port USB KVM Switch is the perfect choice for managing multiple PC's.

PRODUCT OVERVIEW

- 8-port KVM switch with VGA and USB connection to computers
- Supports both USB and PS/2 connections to console port
- Device monitoring with adjustable Auto-Scan and audible feedback
- Supports most operating systems and advance mouse designs

FEATURES

- Controls up to 8 computers or servers.
- Supports both USB and PS/2 Interface for console port
- Supports Windows®, Linux®, Mac OS® and more
- High video quality, up to 2048 x 1536 VGA resolution
- Firmware upgradeable via PC port
- Auto-scan for monitored PCs with adjustable scan interval from 10-99 seconds
- Keyboard status restored when switching between computers
- LEDs display for easy status monitoring
- Beeping sound for port switching confirmation (enable/disable)
- Keyboard hot key command or push button switching
- Plug & Play and Hot-Pluggable
- Standard 19" (1U) rack mount design
- 2-year limited warranty

8-Port Rack Mount KVM Switch

TK-803R (v1.1R)




SPECIFICATIONS

HARDWARE

Connections	• 8 computers/servers	
Standard	• USB 1.1 Compliant	
PC Ports	• 8 x VGA HDB 15-pin (female)	
Console Port	• 1 x USB (Type A)/PS/2 (6-pin mini-DIN) mouse • 1 x USB (Type A)/PS/2 (6-pin mini-DIN) keyboard • 1 x VGA HDB 15-pin (female)	
Cable Interface (Sold Separately)	To KVM 1 x VGA HDB 15-pin (male)	To Computer 1 x VGA HDB 15-pin (male) 1 x USB (Type A)
Supported OS	• Windows®, Linux, Mac® and more	
PC Selection	• Keyboard hot key command or push button	
Auto-Scan Interval	• 10-99 seconds (Programmable through hot key)	
LEDs	• On-line (Red), Select (Green)	
Keyboard Status	• Saved & restored	
Power Adapter	• Input: 100 ~ 240 V AC 50~60 Hz • Output: 9 V DC 1 A external power adapter	
Dimensions	• 407 x 165 x 45 mm (16.0 x 6.5 x 1.8 in.)	
Weight	• 1.83 kg (4.0 lb)	
Temperature	• Operating: 0 - 40°C (32 - 104°F) • Storage: -20 - 60°C (-4 - 140°F)	
Humidity	• Max. 80% (non-condensing)	
Certification	• CE, FCC	

NETWORKING SOLUTIONS

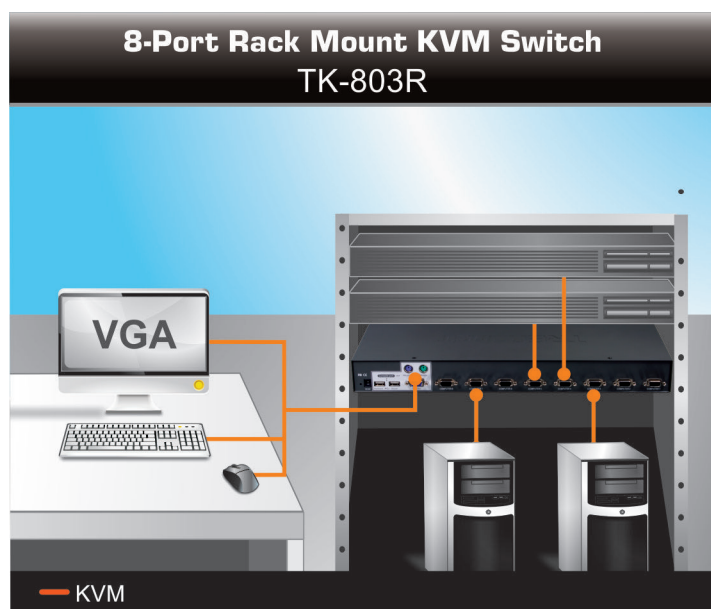

PACKAGE CONTENTS

TK-803R

Quick Installation Guide

Power Adapter (9 V DC, 1 A)

Rack mount kit

RELATED PRODUCTS

TK-1603R	16-Port Rack Mount USB KVM Switch
TK-CU06	6 ft USB/VGA KVM cable
TK-CU10	10 ft USB/VGA KVM cable
TK-CU15	15 ft USB/VGA KVM cable

CONTACT INFORMATION

TRENDnet®

20675 Manhattan Place, Torrance, CA 90501 USA

Tel: 1-310-961-5500

Fax: 1-310-961-5511

Web: www.trendnet.com

Email: sales@trendnet.com

1-888-326-6061

