


19512702	DATA SHEET	
Valid from: 09.08.2018	EPIC® ULTRA H-A 3 AGSV M20	

Description

- EMC protection
- Corrosion-resistant
- Protection rating UL50E tested
- All-purpose due to high corrosion resistance and high environmental protection

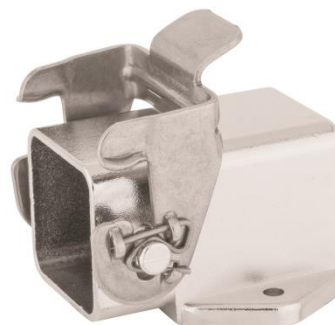

General Characteristics

Series	ULTRA H-A 3
Version	Surface-mount base M20
Locking mechanism	Single lever
Cable entry	Straight
Thread	M20x1.5
Protection (DIN EN 60529)	IP 65 (latched)
Protection (NEMA 250, UL50E)	4, 4X, 12 (latched)
Temperature range	-40°C to +100°C, short-term up to +125°C
Holding screws for inserts included	Yes
Cable Gland included	No

Materials and Surfaces

Housing, base material	Zinc die-casting
Housing, surface	Nickel-plated
Lever	Stainless steel
Holding screws for inserts	Stainless steel
Gasket	NBR

Approvals

VDE-Approval, VDE-REG.-Nr.	B437
UL-Approval UL-E-File Number	E75770


Standards

Safety Standard	IEC 61984; UL 1977
-----------------	--------------------

Creator: BEGE1/PDP Released: IVSE1/PDP	Document: DB19512702EN Version: 00	Page 1 of 2
---	---------------------------------------	-------------

19512702	DATA SHEET	
Valid from: 09.08.2018	EPIC® ULTRA H-A 3 AGSV M20	

Technical Drawing

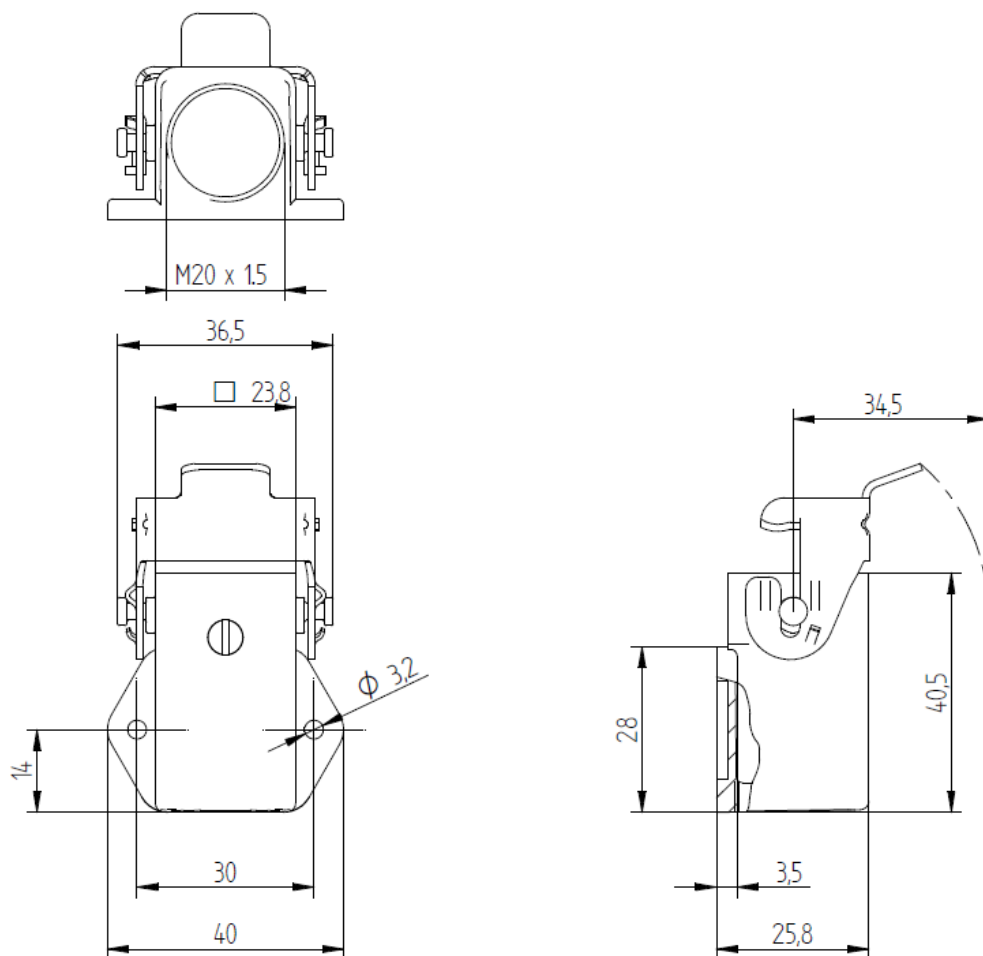

Remark

Photographs are not to scale and do not represent detailed images of the respective products.

Creator: BEGE1/PDP Released: IVSE1/PDP	Document: DB19512702EN Version: 00	Page 2 of 2
---	---------------------------------------	-------------