

10152000	DATA SHEET	
Valid from: 01.04.2022	EPIC® H-B 48 AD	

Description

- The large, robust housing for two inserts in one connector
- Power and data in one connector



General Characteristics

Series	H-B 48
Version	Panel mount base with cover
Locking	Single lever
Protection (DIN EN 60529)	IP 65 (latched with hood)
Temperature Range	-40°C to +100°C, short term up to +125°C

Materials / Surfaces

Housing	Aluminium alloy, powder-coated, grey
Locking	Steel, zinc-plated
Sealing	NBR
Cover	PA

Standard


Safety Standard	IEC 61984
-----------------	-----------

Versions

Article number	Article description
10152000	EPIC® H-B 48 AD

10152000	DATA SHEET	
Valid from: 01.04.2022	EPIC® H-B 48 AD	

Technical Drawings

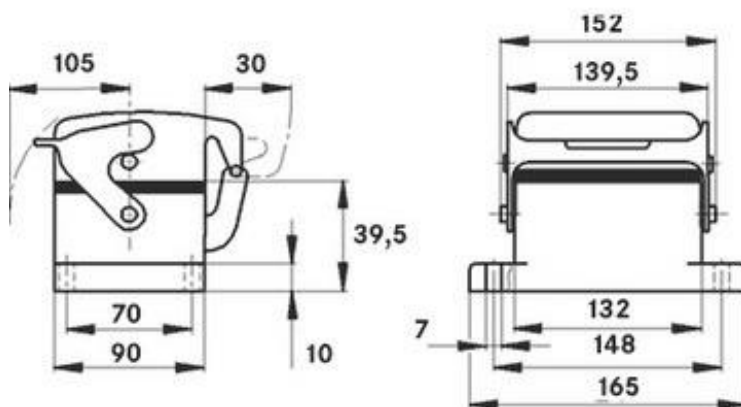

Industrial machinery and plant engineering



Mechanical resistance



Robust



Waterproof

Application range

Plant engineering, Plastics industry

Remark

Photographs are not to scale and do not represent detailed images of the respective products.

Creator: BEGE1/PDP Released: IVSE1/PDP	Document: DB10152000EN Version: 00	Page 2 of 2
---	---------------------------------------	-------------