


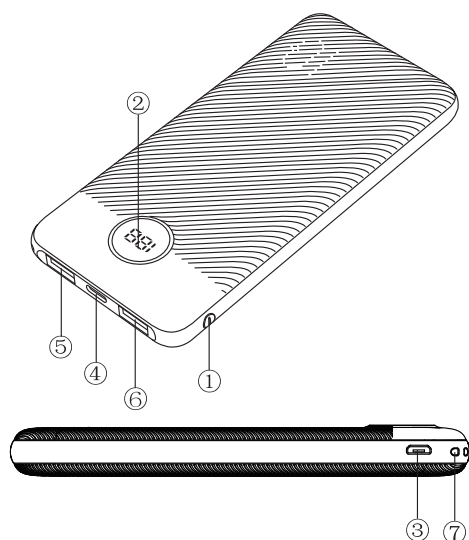

PRODUCT COMPONENT INTRODUCTION

- ① Button
- ② Digital Display
- ③ Micro USB Input
- ④ Type-C Input/Output
- ⑤ USB Output 1
- ⑥ USB Output 2
- ⑦ Lanyard Hole

XCell Powerbank X10000PD	
Highlight	Ultra Slim Design; LCD Display, Precise Power Display; PD Fast Charging
Capacity	10000mAh
Battery Voltage	3.7V
Battery Power	37Wh
Product Size	142.8*67.6*15.9mm
Power Display	LED Display Screen
Product Net Weight	220g
Materials	Plastic
Finish&Surface	Scrubs
Total Input (Max)	PD18W/QC18W
Input Port	Micro USB & Type-C
Total Output (Max)	PD20W
Type-C + USB-A Max Output	5V-3A
USB 1 Output	(QC3.0) 5V-3A/9V-2.0A/12V-1.5A
USB 2 Output	(QC3.0) 5V-3A/9V-2.0A/12V-1.5A
Type-C 1 Output	(PD+QC3.0) 5V-3.0A/9V-2.2A/12V-1.66A
Comptiable With	Smartphone, Tablet, Consule, TWS Earbud, etc
Packaging List	Power Bank X1, USB-A to Type-C Cable X1, Warranty Card X1, User Manuals X1
Packaging Size (cm)	16.8*10*2.2
Product Net Weight(g)	220
Packaging Weight(g)	268
Carton Size (cm)	36.5*32*23
Quantity Per Carton	50
Carton G.W (kgs)	14,1
Carton N.W (kgs)	13,4