


specifications

Tak-Ty™ Hook & Loop Cable Ties and Rolls shall be made of soft premium material which shall be safe to use on high performance cabling. This material shall aid in protecting from over tensioning. The Hook & Loop Cable Ties shall provide a broad section of durable designs and sizes. This hook and loop product shall be available in the following colours: black, red, yellow, blue, white, erika violet, lime green and aqua. Hook and loop shall be adjustable and reusable and shall be cycled 100+ times. The Panduit™ Hook & Loop shall hold its strength even at higher temperatures. It shall be a cost-effective method for properly bundling cable and can enhance traceability. Hook and loop shall come in a variety of packages as showcased below:

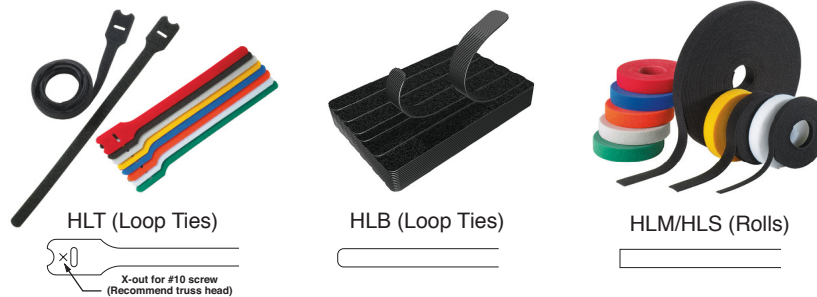

technical information

Material: Hooks: Nylon
Loops: Nylon

Minimum loop tensile strength: 50 lbs. 222 N

key features and benefits

Premium hook and loop Can be resealed over 100 times and can maintain strength at high temperatures.

Available in a variety of colours and styles Colour options aid in providing traceability and protection when bundling cables.

Loop Ties

Part Number	Mounting Method
HLT2I-X*	Hook and Loop Cable Tie, Low Profile, 8"L (203mm), .5"W (12.7mm)
HLT3I-X*	Hook and Loop Cable Tie, Low Profile, 12"L (305mm), .5"W (12.7mm)
HLT2I-M0	Hook and Loop Cable Tie, Low Profile, 8"L (203mm), .5"W (12.7mm), 1000PCS
HLT3I-M0	Hook and Loop Cable Tie, Low Profile, 12"L (305mm), .5"W (12.7mm), 1000PCS

*-X0 Black, -X2 Red, -X4 Yellow, -X6 Blue, -X7 Erika Violet, -X10 White, -X15 Lime Green, -X16 Aqua

Stacked Strip Ties

Part Number	Mounting Method
HLB2S-C0	Hook & Loop Stacked Strip Ties, 7.0L (178mm), .75W (19.1mm), 100 PCS, Black

Continuous Roll 15' and 75'

Part Number	Description	Colour
HLM-15R*	Hook and Loop Roll, 15'L (4.6m), .33"W (8.4mm)	Various
HLS-15R*	Hook and Loop Roll, 15'L (4.6m), .75"W (19.1mm)	Various
HLS-75R*	Hook and Loop Roll, 75'L (22.9m), .75"W (19.1mm)	Various

*-R0 Black, -R2 Red, -R4 Yellow, -R6 Blue, -R7 Erika Violet, -R10 White, -R15 Lime Green, -R16 Aqua

WORLDWIDE SUBSIDIARIES AND SALES OFFICES

PANDUIT US/CANADA
Phone: 800.777.3300

PANDUIT EUROPE LTD.
London, UK
Phone: 44.20.8601.7200

PANDUIT SINGAPORE PTE. LTD.
Republic of Singapore
Phone: 65.6305.7575

PANDUIT JAPAN
Tokyo, Japan
Phone: 81.3.6863.6000

PANDUIT LATIN AMERICA
Guadalajara, Mexico
Phone: 52.33.3777.6000

PANDUIT AUSTRALIA PTY. LTD.
Victoria, Australia
Phone: 61.3.9794.9020

For a copy of Panduit product warranties, log on to www.panduit.com/warranty