

52103500	DATA SHEET	
Valid from: 26.08.2024	SKINDICHT® SM-NPT INOX	


The SKINDICHT® SM-NPT INOX is a stainless steel hex locknut.
 The locknut is used where cable glands are attached but there is only a pass-through hole.



Technical features:

Material	Stainless steel (AISI 304)
Sizes	1/2” up to 2” NPT
Temperature range	-60 °C up to +200 °C

Norm-Referenzen:

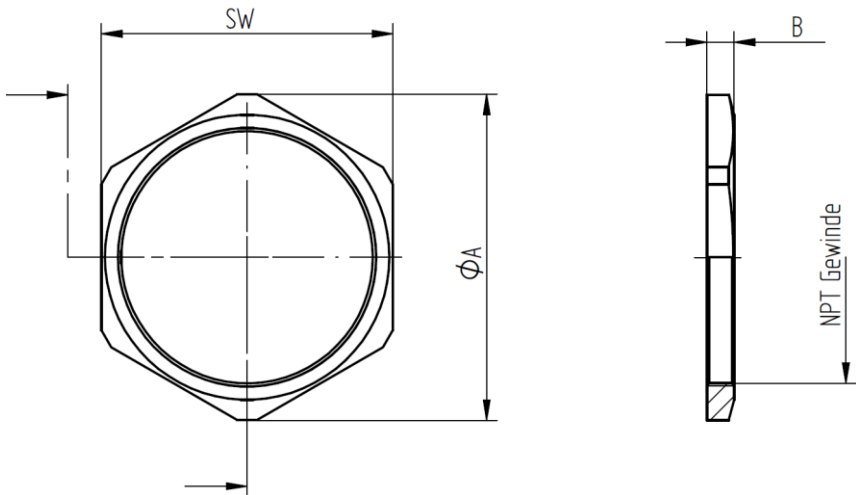

NPT	SW [mm]	Ø A [mm]	B [mm]	Art. Nr.
1/2“	27	30,0	4,0	5210 3500
3/4“	32	35	4,5	5210 3510
1“	38	42	6,0	5210 3520
1 1/4“	48	53	6,5	5210 3530
1 1/2“	55	61	7,0	5210 3531
2“	70	78	7,5	5210 3532

For more information please see our current catalogue. Please do not hesitate to contact our laboratory if there are any questions regarding resistance against aggressive agents and special oil.

Creator: MAU1/PDP Released: DAMU1/PDP	Document: DB52103500EN Version: 02	Page 1 of 1
--	---------------------------------------	-------------