

52006460	DATA SHEET	
Valid from: 03.07.2018	SKINDICHT® SVRX-W	

The SKINDICHT® SVRX-W is a range of brass cable glands by DIN 89280 with round gland body.



The cable gland is shown with counter nut SKINDICHT® SM/SVRX

Components:

Gland body	Brass, bright
Pressure screw	Brass, bright
Sealing ring	Ethylene-Propylene-Diene-Monomer rubber (EPDM)
Pressure washers	Brass, bright

Technical features:

Connecting thread	M56x2 up to M105x2 acc. to DIN 13
Protection class	IP56 acc. to EN 60529
Temperature range	-20 °C up to +80 °C

Norm references:




Note:

Counter nut to be used: SKINDICHT® SM/SVRX

Creator: T. Dvoutely /PDP Released: DAMU1/PDP	Document: DB52006460EN Version: 03	Page 1 of 2
--	---------------------------------------	-------------

52006460	DATA SHEET	
Valid from: 03.07.2018	SKINDICHT® SVRX-W	

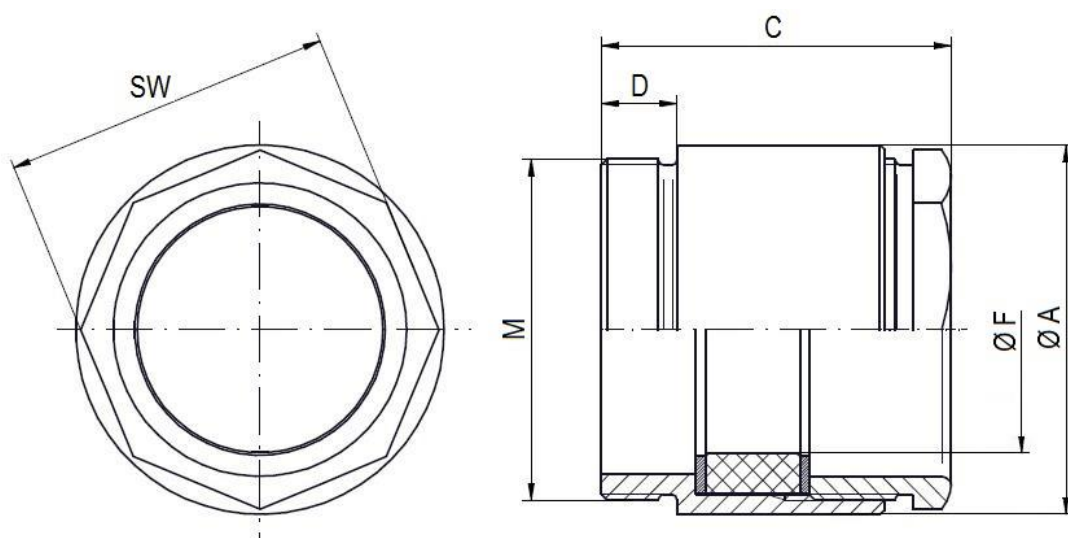

M	SW [mm]	Ø A [mm]	C [mm]	D [mm]	Ø F [mm] Clamping range	Article No.
M56x2	55	62	69	15	32-35,5	52006460
	55	62	69	15	35-38,5	52006470
	55	62	69	15	38-41,5	52006480
M72x2	70	78	74	16	41-44,5	52006490
	70	78	74	16	44-48,5	52006500
	70	78	74	16	48-52,5	52006510
	70	78	74	16	52-56,5	52006520
M80x2	85	90	82	18	56-59	52006564
	85	90	82	18	62-66	52006530
M105x2	104	115	93	20	68-73	52006540
	104	115	93	20	78-83	52006550

For more information please see our current catalogue. Please do not hesitate to contact our laboratory if there are any questions regarding resistance against aggressive agents and special oil.

Creator: T. Dvoutely /PDP Released: DAMU1/PDP	Document: DB52006460EN Version: 03	Page 2 of 2
--	---------------------------------------	-------------