

52104730	DATA SHEET	
Valid from: 06.02.2025	SKINDICHT® TWIST-M	

The SKINDICHT® TWIST-M is a 360° swivel coupler, which is made of nickel plated brass, for using with metric SILVYN® conduit glands.
The coupler is suitable for the positioning of elbowed fitting and the prevention of damage by torsional motion on rigid protection conduit systems.

Material:

Body	Brass, nickel plated
Snap ring	Spring steel
Sealing	FKM



Technical Features:


Connecting thread	M12x1,5 up to M25x1,5 acc. to DIN EN 60423
Protection class coupler	IP66 acc. to DIN EN 60529 IP68 – 5bar / 30min acc. to DIN EN 60529 Depending on the used SILVYN® protection conduit system
Temperature range	-20°C up to +200°C

Norm references:



Notes:

The coupler is no substitution for ball- or roller bearings!

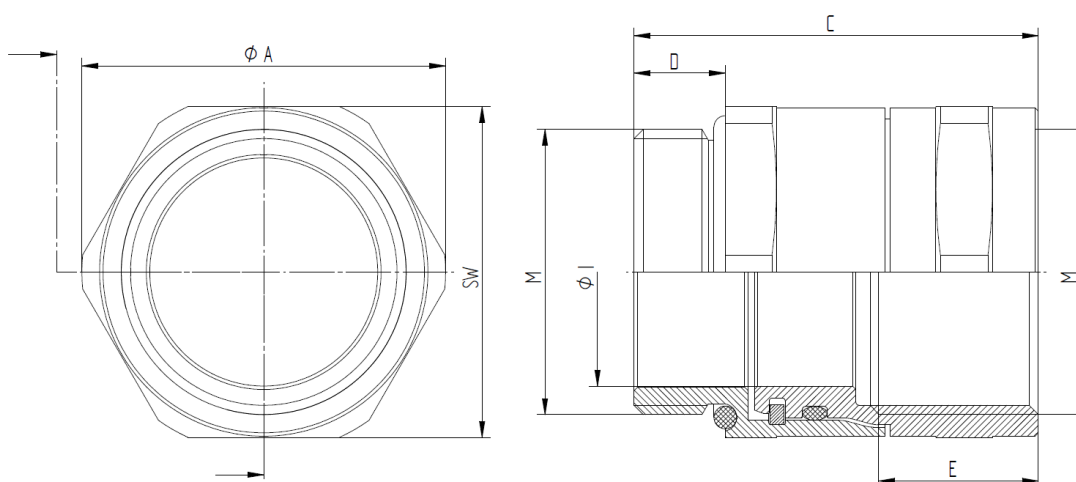

Dimension table:

Part No.	Thread M	Wrench size SW	Thread length mm		Diameter mm		Length mm C
			D	E	Ø A	Ø I	
52104730	M12 x 1,5	16	6,5	12,5	17,6	8,0	29,0
52104731	M16 x 1,5	20	7,0	13,0	22,0	11,0	30,5
52104732	M20 x 1,5	24	8,0	14,5	26,4	14,5	34,5
52104733	M25 x 1,5	29	8,0	14,5	31,9	20,0	35,5

For more information please see our current catalogue. Please do not hesitate to contact our laboratory if there are any questions regarding resistance against aggressive agents and special oil.

Creator: MAU1/PDP Released: DAMU1/PDP	Document: DB52104730EN Version: 04	Page 1 of 1
--	---------------------------------------	-------------