


	DATA SHEET	
Valid from: 21.01.2019	FLEXIMARK® Flexilabel LFL	

For cable, pipe and component marking. Mounted in FLEXIMARK® Character holders. Both sides of the label are printable.
Supplied on perforated A4 sheets.

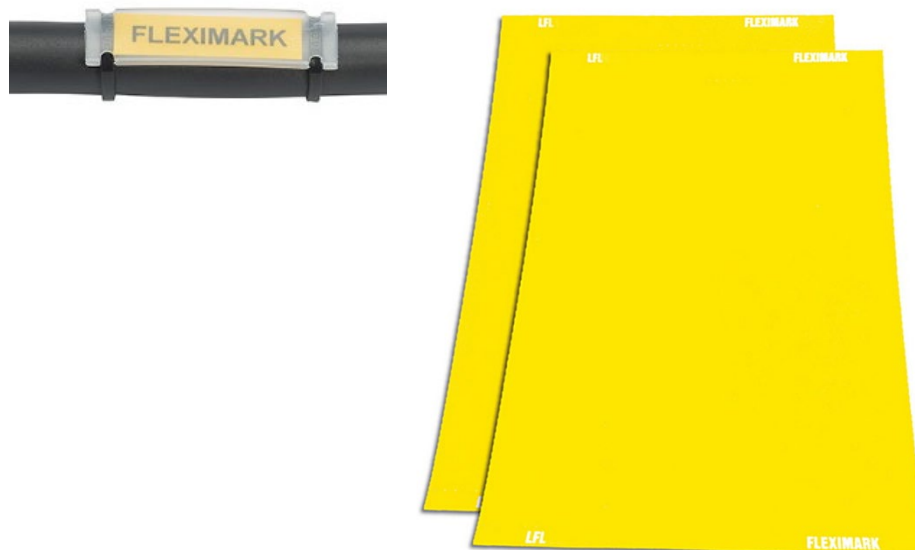

Technical data:

Material:	Polyester, halogen free, UV-resistant
Operating temperature:	-40°C to +125°C
Sheet size:	A5, A4
Colour:	Yellow/White
Recommended storage:	21°C and 50% RH

Mounting:

Mounted in FLEXIMARK® Character holders.

Other product data:

ETIM Classification:	EC001288
----------------------	----------

Advantages:

Supplied as punched and perforated A4 sheets.
Printed in standard office laser printers, both sides are printable.
Durable and flexible mounting.

Creator: Fleximark/LR	Document: DB83254620EN Version: 00	Page 1 of 2
-----------------------	---------------------------------------	-------------


	DATA SHEET	
Valid from: 21.01.2019	FLEXIMARK® Flexilabel LFL	

Product data:

E-nummer	LAPP Part no.	Article designation	Size/ Label WxH mm	Content/ unit	colour	Content (Unit)
2972690	83254620	LFL 6-35 YE/WH flexilabel	6x35	235	Yellow/White	10
2972326	83254650	LFL 9.5-17.5 YE/WH flexilabel	9,5x17,5	319	Yellow/White	10
2972079	83254660	LFL 9.5-28 YE/WH flexilabel	9,5x28	203	Yellow/White	10
2972057	83254670	LFL 9.5-35 YE/WH flexilabel	9,5x35	145	Yellow/White	10
2972330	83254690	LFL 9.5-196 YE/WH flexilabel	9,5x196	29	Yellow/White	10
2972081	83254710	LFL 12-38 YE/WH flexilabel	12x38	115	Yellow/White	10
2972083	83254718	LFL 19-50 YE/WH Flexilabel	19x50	56	Yellow/White	10
2941262	83254719	LFL 19-100 YE/WH flexilabel	19x100	28	Yellow/White	10

Related products

FLEXIMARK® Flexilabel LFL can be printed using FLEXIMARK® Software and an office laser printer. Select label in the label selector in the program, add to the table what to print, select printer and print.

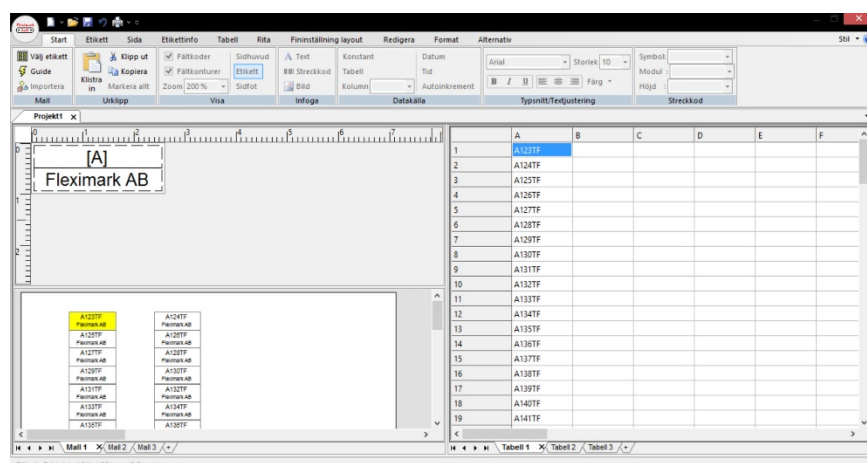

Easily mounted with FLEXIMARK® Character holders PTEF, CAB and PTE.



Note:

Pictures are not to scale and do not represent detailed images of each product.

Creator: Fleximark/LR	Document: DB83254620EN Version: 00	Page 2 of 2
-----------------------	---------------------------------------	-------------