

83254222	DATA SHEET	
Valid from: 17.09.2018	FLEXIMARK® KIT STAINLESS STEEL	



FLEXIMARK® KIT STAINLESS STEEL (with or without cable tie plier)



General description:

- Industrial system for marking cables, pipes, components and devices in demanding and aggressive environment
- Mounting together with FLEXIMARK® Stainless steel cable ties and FLEXIMARK® Cable tie plier or screws
- Delivered as kit in a box (400x300x45mm)
- Included with everything you need for industrial marking; i.e. characters, character holders and cable ties (for details, please see the content list). All details included are available for reorder.

Technical data:

- Material: Stainless steel SIS SS2348 (AISI-316)
- Resistance: High acid, UV, diesel, water, alkali and oil resistance
- Temperature range: <500°C
- Approvals: Stainless steel material: Achilles, High chemical resistance (SP Tested by an independent expert)

Part no.	Article designation	FLEXIMARK® Cable tie pliers	Content (unit)	PU
83254222	FLEXIMARK KIT STAINLESS STEEL	No	1	1
83254223	FLEXIMARK KIT STAINLESS STEEL WITH PLIERS	No	1	1
83254224	FLEXIMARK KIT WITH CABLE TIE PLIERS	Yes	1	1

Resistance of FLEXIMARK® Stainless steel material

(SP tested by an independent expert)

	UV resistance	Ageing resistance	Diesel resistance	Acid (H ₂ SO ₄) 25%	Alkali (Detergent solution, 10%)	Distilled water	Salt water (5% NaCl)	Transformer oil (Nytro 10X)	Ethanol
<i>Stainless steel SIS SS2348 (AISI316)</i>	Tested Recommended	Tested Recommended	Tested Recommended	Tested Recommended	Tested Recommended	Tested Recommended	Tested Recommended	Tested Recommended	Tested Recommended

Testresult Acid proof cable sign (SP test):

Ageing 200h +90°C

Function well. No cracks or other visible damages. The surface of the sign is apparently unchanged. The print is fully readable.

Elaborated by: FLEXIMARK: A. Lindberg	Document: DB83254222EN Version: 01	Page 1 of 3
--	---------------------------------------	-------------

83254222	DATA SHEET	
Valid from: 17.09.2018	FLEXIMARK® KIT STAINLESS STEEL	

Chemical resistance


Function well. The print is fully readable.

Advantages:

- High quality and durability of the marking due to material stainless steel SIS SS2348 (AISI-316)
- Marking suitable for demanding and aggressive environment
- Can be used for both component and cable marking
- High resistance towards different strains and chemicals
- Possibility to produce your own stainless steel marking manually on the site
- All including articles can be reordered
- New box offers good overview and storage of all products, keeping them in place at all time
- Small strip cases inside the box help you keep the order and saves time by easily finding the right product

FLEXIMARK® Stainless steel Characters

are delivered in strips with break marks for easy and quick mounting.

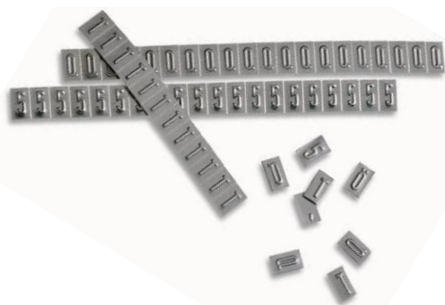

FLEXIMARK® Stainless steel holders are for cable and component marking. Mounting together with FLEXIMARK® Stainless steel characters.



FLEXIMARK® Stainless steel NM holders are for cable and component marking and mounting with FLEXIMARK® Stainless steel cable ties or screw.

FLEXIMARK® Stainless steel M holders are for component marking and mounting with screw.

FLEXIMARK® Stainless steel cable ties, also

available with polyester coating are used for mounting NM character holders onto the cable. Mounted with the help of FLEXIMARK® Stainless steel cable tie plier.



Self-locking cable ties with steel ball at the end of the tie for easy mounting.

If pulled in the opposite direction to re-open or loosen the tie, the ball is locked at the end of the tie and re-opening is impossible

FLEXIMARK® Stainless steel cable tie pliers

Handy processing tool for FLEXIMARK® Stainless steel ties (up to 0.3mm thickness).



Cable tie is automatically cut at its end once the required tension is achieved.



Stripping force can be adjusted in increments.

Special pliers (include in box 83254223)

Elaborated by: FLEXIMARK: A. Lindberg	Document: DB83254222EN Version: 01	Page 2 of 3
--	---------------------------------------	-------------

83254222	DATA SHEET	
Valid from: 17.09.2018	FLEXIMARK® KIT STAINLESS STEEL	

Content in FLEXIMARK® KIT STAINLESS STEEL:

ARTICLE NUMBER	DESCRIPTION	ARTICLE DETAILS	AMOUNT
83254150	FLEXIMARK MR10-20-A STAINLESS STEEL	A	40pcs
83254151	FLEXIMARK MR10-20-B STAINLESS STEEL	B	40pcs
83254152	FLEXIMARK MR10-20-C STAINLESS STEEL	C	40pcs
83254153	FLEXIMARK MR10-20-D STAINLESS STEEL	D	40pcs
83254154	FLEXIMARK MR10-20-E STAINLESS STEEL	E	40pcs
83254155	FLEXIMARK MR10-20-F STAINLESS STEEL	F	40pcs
83254156	FLEXIMARK MR10-20-G STAINLESS STEEL	G	40pcs
83254157	FLEXIMARK MR10-20-H STAINLESS STEEL	H	40pcs
83254158	FLEXIMARK MR10-20-I STAINLESS STEEL	I	40pcs
83254159	FLEXIMARK MR10-20-J STAINLESS STEEL	J	40pcs
83254160	FLEXIMARK MR10-20-K STAINLESS STEEL	K	40pcs
83254161	FLEXIMARK MR10-20-L STAINLESS STEEL	L	40pcs
83254162	FLEXIMARK MR10-20-M STAINLESS STEEL	M	40pcs
83254163	FLEXIMARK MR10-20-N STAINLESS STEEL	N	40pcs
83254164	FLEXIMARK MR10-20-O STAINLESS STEEL	O	40pcs
83254165	FLEXIMARK MR10-20-P STAINLESS STEEL	P	40pcs
83254166	FLEXIMARK MR10-20-Q STAINLESS STEEL	Q	40pcs
83254167	FLEXIMARK MR10-20-R STAINLESS STEEL	R	40pcs
83254168	FLEXIMARK MR10-20-S STAINLESS STEEL	S	40pcs
83254169	FLEXIMARK MR10-20-T STAINLESS STEEL	T	40pcs
83254170	FLEXIMARK MR10-20-U STAINLESS STEEL	U	40pcs
83254171	FLEXIMARK MR10-20-V STAINLESS STEEL	V	40pcs
83254172	FLEXIMARK MR10-20-W STAINLESS STEEL	W	40pcs
83254173	FLEXIMARK MR10-20-X STAINLESS STEEL	X	40pcs
83254174	FLEXIMARK MR10-20-Y STAINLESS STEEL	Y	40pcs
83254175	FLEXIMARK MR10-20-Z STAINLESS STEEL	Z	40pcs
83254176	FLEXIMARK MR10-20-Å STAINLESS STEEL	Å	40pcs
83254177	FLEXIMARK MR10-20-Ä STAINLESS STEEL	Ä	40pcs
83254178	FLEXIMARK MR10-20-Ö STAINLESS STEEL	Ö	40pcs
83254179	FLEXIMARK MR10-20-1 STAINLESS STEEL	1	40pcs
83254180	FLEXIMARK MR10-20-2 STAINLESS STEEL	2	40pcs
83254181	FLEXIMARK MR10-20-3 STAINLESS STEEL	3	40pcs
83254182	FLEXIMARK MR10-20-4 STAINLESS STEEL	4	40pcs
83254183	FLEXIMARK MR10-20-5 STAINLESS STEEL	5	40pcs
83254184	FLEXIMARK MR10-20-6 STAINLESS STEEL	6	40pcs
83254185	FLEXIMARK MR10-20-7 STAINLESS STEEL	7	40pcs
83254186	FLEXIMARK MR10-20-8 STAINLESS STEEL	8	40pcs
83254187	FLEXIMARK MR10-20-9 STAINLESS STEEL	9	40pcs
83254164	FLEXIMARK MR10-20-O STAINLESS STEEL	0	40pcs
83254192	FLEXIMARK MR10-20+ STAINLESS STEEL	+	40pcs
83254191	FLEXIMARK MR10-20- STAINLESS STEEL	-	40pcs
83254195	FLEXIMARK MR10-20- STAINLESS STEEL	.	40pcs
83254193	FLEXIMARK MR10-20= STAINLESS STEEL	=	40pcs
83254201	FLEXIMARK MR10-20-Ü STAINLESS STEEL	Ü	40pcs
83254200	FLEXIMARK MR10-20-EA STAINLESS STEEL	EA	40pcs
83254189	FLEXIMARK MRP10-20 STAINLESS STEEL	BLANK	40pcs
83254194	FLEXIMARK MR10-20-/ STAINLESS STEEL	/	40pcs
83254199	FLEXIMARK MR10-20: STAINLESS STEEL	:	40pcs
83254197	FLEXIMARK MR10-20-x STAINLESS STEEL	x	40pcs
83254196	FLEXIMARK MR10-20-, STAINLESS STEEL	,	40pcs
83254210	FLEXIMARK PR10 NM24 STAINLESS STEEL CHARACTER HOLDER	HOLDER NM24	5pcs
83254211	FLEXIMARK PR10 NM9 STAINLESS STEEL CHARACTER HOLDER	HOLDER NM9	5pcs
83254212	FLEXIMARK PR10 NM7 STAINLESS STEEL CHARACTER HOLDER	HOLDER NM7	5pcs
83254213	FLEXIMARK PR10 NM5 STAINLESS STEEL CHARACTER HOLDER	HOLDER NM5	5pcs
83254214	FLEXIMARK PR10 NM4 STAINLESS STEEL CHARACTER HOLDER	HOLDER NM4	5pcs
83254101	FLEXIMARK PR10 M24 STAINLESS STEEL CHARACTER HOLDER	HOLDER M24	5pcs
83254102	FLEXIMARK PR10 M9 STAINLESS STEEL CHARACTER HOLDER	HOLDER M9	5pcs
83254103	FLEXIMARK PR10 M7 STAINLESS STEEL CHARACTER HOLDER	HOLDER M7	5pcs
83254104	FLEXIMARK PR10 M5 STAINLESS STEEL CHARACTER HOLDER	HOLDER M5	5pcs
83254105	FLEXIMARK PR10 M4 STAINLESS STEEL CHARACTER HOLDER	HOLDER M4	5pcs
61812950	FLEXIMARK FSBT 4.6*200 STAINLESS STEEL CABLE TIES	CABLE TIES 4.6x200mm	100pcs
83250022	FLEXIMARK STAINLESS STEEL CABLE TIE PLIER HT-338 (83254224)	PLIER (83254224)	1 (83254224)
83251991	FLEXIMARK KIT EMPTY	EMPTY BOX	1pcs
83251990	FLEXIMARK STRIP CASE KIT	CASE FOR CHARACTER STRIPS	50pcs

Foot note:

Photographs are not to scale and do not represent detailed images of the respective products.

Elaborated by: FLEXIMARK: A. Lindberg	Document: DB83254222EN Version: 01	Page 3 of 3
--	---------------------------------------	-------------