

Datasheet – TRU Components

Item no.: 3527284 - 288




Pneumatic connector set

Pneumatic connectors set


- Pressure range: 0 – 10 bar
- Negative pressure: - 1 bar (10 Torr)
- Max. pressure: 15 bar
- Temperature range: -10 80 °C




PU

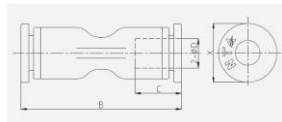


PE

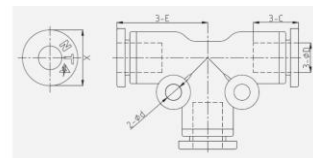

PY

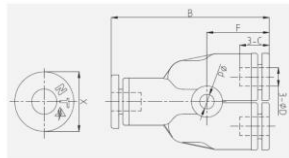

PV

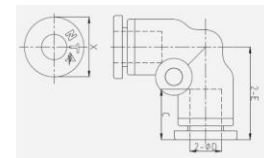

Item No.: 3527284 – 4 mm Set (80 pcs)

Item No.	Model No.	Qty	D	B	F	C	X	d	E
2615637	PU4	20	4	33.4	-	15.3	9.9	-	-
2615652	PE4	20	4	-	-	15.3	9.9	3.3	17.9
2615647	PY4	20	4	35.9	14.2	15.3	9.9	3.3	-
2615642	PV4	20	4	-	-	15.3	9.9	3.3	17.9

Item No.: 3527285 – 6 mm Set (60 pcs)

Item No.	Model No.	Qty	D	B	F	C	X	d	E
2615638	PU6	15	6	35.5	-	16.7	11.8	-	-
2615653	PE6	15	6	-	-	16.7	11.8	3.2	20.3
2615648	PY6	15	6	38.5	15	16.7	11.8	3.2	-
2615643	PV6	15	6	-	-	16.7	11.8	3.2	20.1

Datasheet – TRU Components

Item no.: 3527284 - 288



Pneumatic connector set

Item No.: 3527286 – 8 mm Set (48 pcs)

Item No.	Model No.	Qty	D	B	F	C	X	d	E
2615639	PU8	12	8	39.5	-	19.1	13.8	-	-
2615654	PE8	12	8	-	-	19.1	13.8	3.3	23.5
2615649	PY8	12	8	43.4	19.7	19.1	13.8	3.3	-
2615644	PV8	12	8	-	-	19.1	13.8	3.3	23.5

Item No.: 3527287 – 10 mm Set (60 pcs)

Item No.	Model No.	Qty	D	B	F	C	X	d	E
2615640	PU10	15	10	46.2	-	21.2	16.8	-	-
2615655	PE10	15	10	-	-	21.2	16.8	4.3	26.8
2615650	PY10	15	10	49	20.5	21.2	16.8	4.3	-
2615645	PV10	15	10	-	-	21.2	16.8	4.3	26.8

Item No.: 3527288 – 12 mm Set (50 pcs)

Item No.	Model No.	Qty	D	B	F	C	X	d	E
2615641	PU12	15	12	50.6	-	24.4	19.8	-	-
2615656	PE12	10	12	-	-	24.4	19.8	4.3	30.8
2615651	PY12	10	12	55.6	22.8	24.4	19.8	4.2	-
2615646	PV12	15	12	-	-	24.4	19.8	4.3	30.8