


BU-31610-*
(Panel Mount Banana Jack)

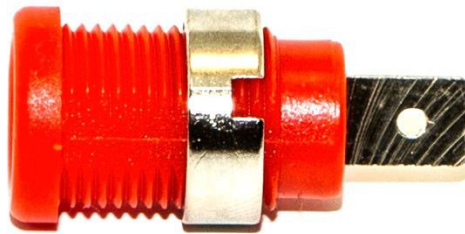

- Mates with all standard 4mm Banana Plugs (shrouded, un-shrouded, or retractable)
- Wire connection is a 1/4" (6.4mm) x .032" (.81mm) Fast-on connector or wire can be soldered to the terminal.
- Recommended mounting hole size is 15/32" (11.9mm). Can mount thru panels up to .4" (10mm) thick
- Material: Housing – Nylon
 Contact – Nickel plated Brass
- Colors: designated by "*" in the part number: -0 black, -2 red
- Ratings: 35 Amps, 1000 V CAT III @105°C MAX.
- RoHS 3 Compliant