


### C5C82UXXX

(Mueller Blue-Flex™, M12 Cordset, 5 Position, 22 AWG, Female Straight to Free End)

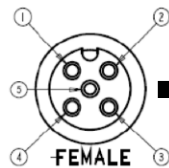

| Pin Out |       |          |
|---------|-------|----------|
| End 1   | Color | End 2    |
| 1       | Brown | Free End |
| 2       | White |          |
| 3       | Blue  |          |
| 4       | Black |          |
| 5       | Grey  |          |

- Mueller's C5C82UXXX is part of Mueller Blue-Flex's™ instrumentation cable offering. The cable is an M12 with a straight female connector on one end and free at the other
- Keyway – A coding
- Utilizes the Mueller Blue-Flex™ cable – 5 conductor, 22AWG, unshielded, silicone outer jacket and inner conductor jacket for maximum flexibility.
- Ratings:
  - Current: 4A
  - Voltage: 60 V AC/DC
- Material
  - Coupling Nuts (anti-vibration) – Nickel Plated Brass (also available in stainless steel)
  - Pins/Contacts – Gold Plated Brass
- Length: The "U" in the model number represents unit of measurement.  
Either: Meters (M), Feet (F)
- Length: The "XXX" in the model number represents length. Standard lengths are 2, 5, and 10 meters. Any other lengths available upon request.
- Meets Standard: IEC 61076-2-101
- Protection Class: IEC IP68
- RoHS 3 Compliant