




DATASHEET

LED Signal Lamp

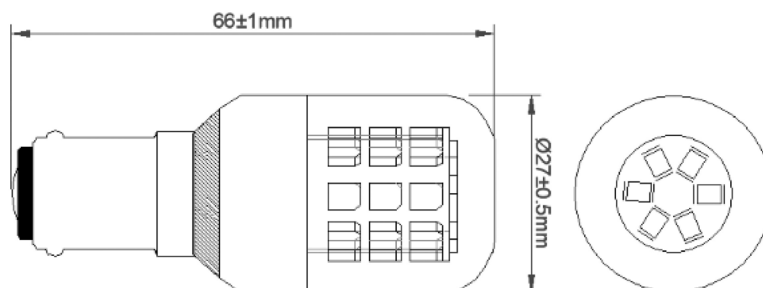

Technical data

Item no.	3531177	3531178	3531179
Rated Voltage	100 - 240 V/AC, 50/60Hz	100 - 240 V/AC, 50/60Hz	100 - 240 V/AC, 50/60Hz
Power	5 W	5 W	5 W
Base	BA15D	BA15D	BA15D
Light color	White (440 - 508 nm)	Green (508 - 522 nm)	Yellow (579 - 600 nm)
Luminous flux	580 lm	500 lm	355 lm
Radiation angle	360°	360°	360°
Current	39 mA	39 mA	39 mA
Head height	22 mm	22 mm	22 mm
Installation depth	16 mm	16 mm	16 mm
Color temperature	6000 k	-	-
Dimmable	No	No	No
Cover material	Glass	Glass	Glass
LED	SMD2835 x 39 LED	SMD2835 x 39 LED	SMD2835 x 39 LED
Lifetime	30000 h	30000 h	30000 h
Operating temperature	-30 to +60 °C	-30 to +60 °C	-30 to +60 °C
Operating humidity	10 - 95 % RH	10 - 95 % RH	10 - 95 % RH
Storage temperature	-30 to +60 °C	-30 to +60 °C	-30 to +60 °C
Storage humidity	10 - 95 % RH	10 - 95 % RH	10 - 95 % RH
Dimensions (Ø x H)	27 x 66 mm	27 x 66 mm	27 x 66 mm
Weight	22 g	22 g	22 g