



Active Stylus Pen

Features

- USI 2.0 Compatible 
- 4096 Pressure Levels 
- Rechargeable Battery 
- Palm Rejection 
- Eraser Button (Depend on App support) 
- Express Button (Depend on App support) 
- Extra 2 Tips 

Technical Specifications


Name / Part No.	Active Stylus Pen / 80-RA000001G001
Stylus Protocol	USI 2.0
Pressure Level	4096
Palm Rejection	Yes
Total Length	160 mm
Pen Diameter	Φ4.00mm
Net Weight	10.5 grams
Sleep Mode	Yes
Wake-Up Method	G-Sensor
LED Status	Charging: the red light is steady on Low battery: the red light blinks Fully charged: the green light is on
Button Status (Depend on App support)	Press and hold: Enter the eraser mode Release: write / drawing mode
Tip Replaceable	Yes Tip Min. Extraction Force: ≥1 N Tip Min. Activation Force: <10 grams
Applicable Force Range	10 ~ 350 grams
Battery Capacity	80 mAh Supply Voltage: 3.8V

Charging Method	Type-C
Battery Life (cruising ability)	Battery Life with Full Charge A) Continuous use(Active) : ≥10 days B) Continuous sleep: more than 80 days C) Shipping mode: more than 1.5 years
Power Consumption	Sleep: <40uA Writing: <2.2mA
Supported Platform	Android OS
Operation Temperature	Temperature: 0° ~ 45° C
Operation Humidity	Humidity: 0 ~ 90%
Operation Temp. for Battery Charge	Temp: 0° ~ 45° C (±2°)
Color	Black
Accessories	User's Manual; 2 x Pen Tips
EAN Code	4711404024764
Certification	CE, RoHS
Packaging	Eco-Friendly Packing



Battery Type Li-ion Battery

Dimensions, Buttons & Connectors

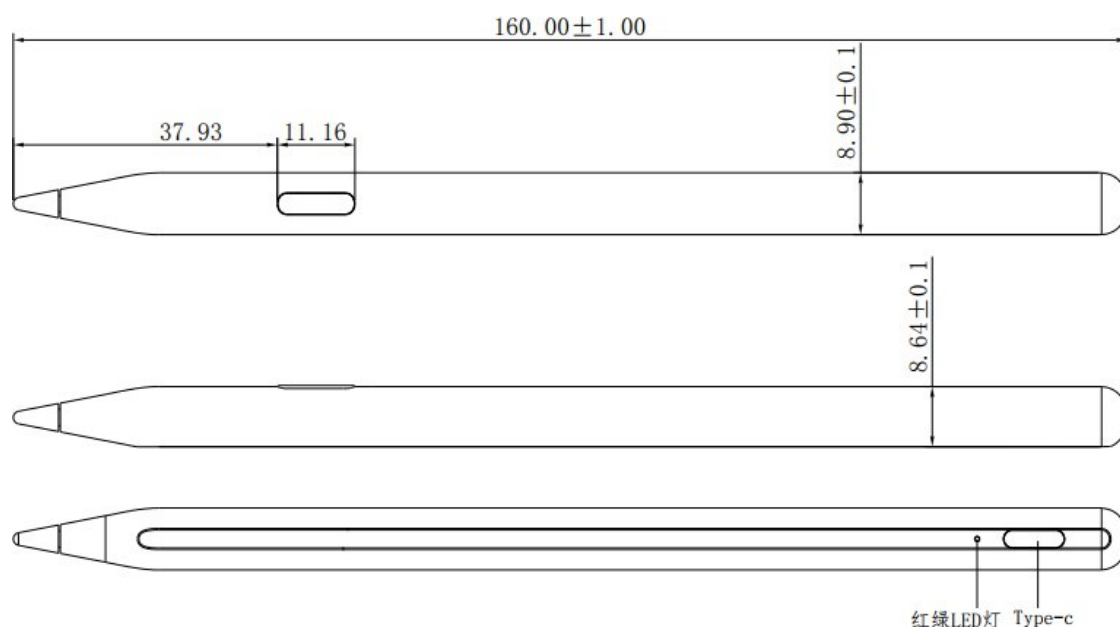

IMPORTANT NOTICE: The battery is not designed to be charged 24/7. Do not attempt to replace the battery yourself, you may damage the battery and this could cause overheating and injury. The lithium-ion battery in the device should be replaced only by HANNspree or a HANNspree Authorized Service Provider, and must be recycled or disposed of separately from household waste. Do not incinerate the battery. For more information about battery recycling and replacement, go to <http://www.hannspree.eu/support/battery-replacement>

© 2024 HANNspree Europe Holdings B.V. Specifications and design as well as accessories are subject to change without notice. Screen shots are simulated. Actual products may differ slightly from those illustrated on this promotion material.

Please refer to actual samples for final selection. The products displayed on this promotion material may not be available for purchase in your particular country or locality. Please check with your local HANNspree authorized representatives for the availability of specific products in your area. Android, Google, Google Play, and the Google Play logo are trademarks of Google Inc.