


Heat-Shrink-Tube Reels 2:1

Item-No.: 24CA261 ... 24CA281, 25CA582 ... 25CA623

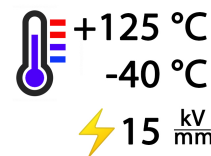

These high-quality shrink sleeves are particularly suitable for service workshops, electronics technicians and applications with a high demand for shrink tubing. The heat-shrink tube is wound onto a cardboard reel and can therefore be cut to length individually. Various available nominal diameters open up a wide range of applications. The standard version with a shrink ratio of 2:1 without internal adhesive is ideal for most applications.

Technical Specifications

Material: PE • Shrink ratio: 2:1 • Shrink temperature (min.): 90 °C • Shrink temperature (max.): 125 °C • Operating temperature: -40 °C ... +125 °C • Tensile strength (min.): 10.4 MPa • Dielectric strength 15 kV/mm (30 s.) • Rated voltage: 600 V • Elongation break: min. 300% • Colors: Black, White, Transparent • Selling unit: Reel or per m.

Item-No.	Description	Diameter	Wall thickness material	Wall thickness shrunk	Content	EAN/GTIN
24CA261	Shrinking tube 2:1 black Φ 1 mm	1 mm	0.16 ($\pm$ 0.02) mm	0.32 ($\pm$ 0.04) mm	200 m	4260732287001
24CA262	Shrinking tube 2:1 black Φ 2 mm	2 mm	0.18 ($\pm$ 0.02) mm	0.36 ($\pm$ 0.04) mm	200 m	4260732287018
24CA263	Shrinking tube 2:1 black Φ 4 mm	4 mm	0.19 ($\pm$ 0.02) mm	0.38 ($\pm$ 0.04) mm	200 m	4260732287025
24CA264	Shrinking tube 2:1 black Φ 6 mm	6 mm	0.21 ($\pm$ 0.02) mm	0.42 ($\pm$ 0.04) mm	100 m	4260732287032
24CA265	Shrinking tube 2:1 black Φ 8 mm	8 mm	0.21 ($\pm$ 0.02) mm	0.42 ($\pm$ 0.04) mm	100 m	4260732287049
24CA266	Shrinking tube 2:1 black Φ 10 mm	10 mm	0.22 ($\pm$ 0.02) mm	0.44 ($\pm$ 0.04) mm	100 m	4260732287056
24CA267	Shrinking tube 2:1 black Φ 12 mm	12 mm	0.23 ($\pm$ 0.02) mm	0.46 ($\pm$ 0.04) mm	100 m	4260732287063
24CA268	Shrinking tube 2:1 black Φ 14 mm	14 mm	0.23 ($\pm$ 0.02) mm	0.46 ($\pm$ 0.04) mm	100 m	4260732287070
24CA269	Shrinking tube 2:1 black Φ 16 mm	16 mm	0.24 ($\pm$ 0.02) mm	0.48 ($\pm$ 0.04) mm	100 m	4260732287087
24CA270	Shrinking tube 2:1 black Φ 18 mm	18 mm	0.24 ($\pm$ 0.02) mm	0.48 ($\pm$ 0.04) mm	50 m	4260732287094
24CA271	Shrinking tube 2:1 black Φ 20 mm	20 mm	0.25 ($\pm$ 0.02) mm	0.5 ($\pm$ 0.04) mm	50 m	4260732287100
24CA272	Shrinking tube 2:1 black Φ 25 mm	25 mm	0.27 ($\pm$ 0.03) mm	0.54 ($\pm$ 0.06) mm	50 m	4260732287117
24CA273	Shrinking tube 2:1 black Φ 30 mm	30 mm	0.28 ($\pm$ 0.03) mm	0.56 ($\pm$ 0.06) mm	25 m	4260732287124
24CA274	Shrinking tube 2:1 black Φ 35 mm	35 mm	0.29 ($\pm$ 0.03) mm	0.58 ($\pm$ 0.06) mm	25 m	4260732287131
24CA275	Shrinking tube 2:1 black Φ 40 mm	40 mm	0.3 ($\pm$ 0.03) mm	0.6 ($\pm$ 0.06) mm	25 m	4260732287148
24CA276	Shrinking tube 2:1 black Φ 50 mm	50 mm	0.33 ($\pm$ 0.03) mm	0.66 ($\pm$ 0.06) mm	25 m	4260732287155
24CA277	Shrinking tube 2:1 black Φ 60 mm	60 mm	0.35 ($\pm$ 0.03) mm	0.7 ($\pm$ 0.06) mm	25 m	4260732287162
24CA278	Shrinking tube 2:1 black Φ 70 mm	70 mm	0.38 ($\pm$ 0.03) mm	0.76 ($\pm$ 0.06) mm	25 m	4260732287179
24CA279	Shrinking tube 2:1 black Φ 80 mm	80 mm	0.4 ($\pm$ 0.03) mm	0.8 ($\pm$ 0.06) mm	25 m	4260732287186
24CA280	Shrinking tube 2:1 black Φ 90 mm	90 mm	0.45 ($\pm$ 0.03) mm	0.9 ($\pm$ 0.06) mm	25 m	4260732287193
24CA281	Shrinking tube 2:1 black Φ 100 mm	100 mm	0.49 ($\pm$ 0.03) mm	0.89 ($\pm$ 0.06) mm	25 m	4260732287209
25CA582	Shrinking tube 2:1 white Φ 1 mm roll 200 m	1 mm	0.16 ($\pm$ 0.02) mm	0.32 ($\pm$ 0.04) mm	200 m	4262511622287
25CA583	Shrinking tube 2:1 white Φ 2 mm roll 200 m	2 mm	0.18 ($\pm$ 0.02) mm	0.36 ($\pm$ 0.04) mm	200 m	4262511622294
25CA584	Shrinking tube 2:1 white Φ 4 mm roll 200 m	4 mm	0.19 ($\pm$ 0.02) mm	0.38 ($\pm$ 0.04) mm	200 m	4262511622300
25CA586	Shrinking tube 2:1 white Φ 8 mm roll 100 m	8 mm	0.21 ($\pm$ 0.02) mm	0.42 ($\pm$ 0.04) mm	100 m	4262511622324
25CA587	Shrinking tube 2:1 white Φ 10 mm roll 100 m	10 mm	0.22 ($\pm$ 0.02) mm	0.44 ($\pm$ 0.04) mm	100 m	4262511622331
25CA588	Shrinking tube 2:1 white Φ 12 mm roll 100 m	12 mm	0.23 ($\pm$ 0.02) mm	0.46 ($\pm$ 0.04) mm	100 m	4262511622348

Continue next page

Item-No.	Description	Diameter	Wall thickness material	Wall thickness shrunk	Content	EAN/GTIN
25CA589	Shrinking tube 2:1 white Φ 14 mm roll 100 m	14 mm	0.23 (± 0.02) mm	0.46 (± 0.04) mm	100 m	4262511622355
25CA590	Shrinking tube 2:1 white Φ 16 mm roll 100 m	16 mm	0.24 (± 0.02) mm	0.48 (± 0.04) mm	100 m	4262511622362
25CA591	Shrinking tube 2:1 white Φ 18 mm roll 50 m	18 mm	0.24 (± 0.02) mm	0.48 (± 0.04) mm	50 m	4262511622379
25CA592	Shrinking tube 2:1 white Φ 20 mm roll 50 m	20 mm	0.25 (± 0.02) mm	0.5 (± 0.04) mm	50 m	4262511622386
25CA593	Shrinking tube 2:1 white Φ 25 mm roll 50 m	25 mm	0.27 (± 0.03) mm	0.54 (± 0.06) mm	50 m	4262511622393
25CA594	Shrinking tube 2:1 white Φ 30 mm roll 25 m	30 mm	0.28 (± 0.03) mm	0.56 (± 0.06) mm	25 m	4262511622409
25CA595	Shrinking tube 2:1 white Φ 35 mm roll 25 m	35 mm	0.29 (± 0.03) mm	0.58 (± 0.06) mm	25 m	4262511622416
25CA596	Shrinking tube 2:1 white Φ 40 mm roll 25 m	40 mm	0.3 (± 0.03) mm	0.6 (± 0.06) mm	25 m	4262511622423
25CA597	Shrinking tube 2:1 white Φ 50 mm roll 25 m	50 mm	0.33 (± 0.03) mm	0.66 (± 0.06) mm	25 m	4262511622430
25CA598	Shrinking tube 2:1 white Φ 60 mm roll 25 m	60 mm	0.35 (± 0.03) mm	0.7 (± 0.06) mm	25 m	4262511622447
25CA599	Shrinking tube 2:1 white Φ 70 mm roll 25 m	70 mm	0.38 (± 0.03) mm	0.76 (± 0.06) mm	25 m	4262511622454
25CA600	Shrinking tube 2:1 white Φ 80 mm roll 25 m	80 mm	0.4 (± 0.03) mm	0.8 (± 0.06) mm	25 m	4262511622461
25CA601	Shrinking tube 2:1 white Φ 90 mm roll 25 m	90 mm	0.45 (± 0.03) mm	0.9 (± 0.06) mm	25 m	4262511622478
25CA602	Shrinking tube 2:1 white Φ 100 mm roll 25 m	100 mm	0.49 (± 0.03) mm	0.89 (± 0.06) mm	25 m	4262511622485
25CA603	Shrinking tube 2:1 transparent Φ 1 mm roll 200 m	1 mm	0.16 (± 0.02) mm	0.32 (± 0.04) mm	200 m	4262511622492
25CA604	Shrinking tube 2:1 transparent Φ 2 mm roll 200 m	2 mm	0.18 (± 0.02) mm	0.36 (± 0.04) mm	200 m	4262511622508
25CA605	Shrinking tube 2:1 transparent Φ 4 mm roll 200 m	4 mm	0.19 (± 0.02) mm	0.38 (± 0.04) mm	200 m	4262511622515
25CA606	Shrinking tube 2:1 transparent Φ 6 mm roll 100 m	6 mm	0.21 (± 0.02) mm	0.42 (± 0.04) mm	100 m	4262511622522
25CA607	Shrinking tube 2:1 transparent Φ 8 mm roll 100 m	8 mm	0.21 (± 0.02) mm	0.42 (± 0.04) mm	100 m	4262511622539
25CA608	Shrinking tube 2:1 transparent Φ 10 mm roll 100 m	10 mm	0.22 (± 0.02) mm	0.44 (± 0.04) mm	100 m	4262511622546
25CA609	Shrinking tube 2:1 transparent Φ 12 mm roll 100 m	12 mm	0.23 (± 0.02) mm	0.46 (± 0.04) mm	100 m	4262511622553
25CA610	Shrinking tube 2:1 transparent Φ 14 mm roll 100 m	14 mm	0.23 (± 0.02) mm	0.46 (± 0.04) mm	100 m	4262511622560
25CA611	Shrinking tube 2:1 transparent Φ 16 mm roll 100 m	16 mm	0.24 (± 0.02) mm	0.48 (± 0.04) mm	100 m	4262511622577
25CA612	Shrinking tube 2:1 transparent Φ 18 mm roll 50 m	18 mm	0.24 (± 0.02) mm	0.48 (± 0.04) mm	50 m	4262511622584
25CA613	Shrinking tube 2:1 transparent Φ 20 mm roll 50 m	20 mm	0.25 (± 0.02) mm	0.5 (± 0.04) mm	50 m	4262511622591
25CA614	Shrinking tube 2:1 transparent Φ 25 mm roll 50 m	25 mm	0.27 (± 0.03) mm	0.54 (± 0.06) mm	50 m	4262511622607
25CA615	Shrinking tube 2:1 transparent Φ 30 mm roll 25 m	30 mm	0.28 (± 0.03) mm	0.56 (± 0.06) mm	25 m	4262511622614
25CA616	Shrinking tube 2:1 transparent Φ 35 mm roll 25 m	35 mm	0.29 (± 0.03) mm	0.58 (± 0.06) mm	25 m	4262511622621
25CA617	Shrinking tube 2:1 transparent Φ 40 mm roll 25 m	40 mm	0.3 (± 0.03) mm	0.6 (± 0.06) mm	25 m	4262511622638
25CA618	Shrinking tube 2:1 transparent Φ 50 mm roll 25 m	50 mm	0.33 (± 0.03) mm	0.66 (± 0.06) mm	25 m	4262511622645
25CA619	Shrinking tube 2:1 transparent Φ 60 mm roll 25 m	60 mm	0.35 (± 0.03) mm	0.7 (± 0.06) mm	25 m	4262511622652
25CA620	Shrinking tube 2:1 transparent Φ 70 mm roll 25 m	70 mm	0.38 (± 0.03) mm	0.76 (± 0.06) mm	25 m	4262511622669
25CA621	Shrinking tube 2:1 transparent Φ 80 mm roll 25 m	80 mm	0.4 (± 0.03) mm	0.8 (± 0.06) mm	25 m	4262511622676
25CA622	Shrinking tube 2:1 transparent Φ 90 mm roll 25 m	90 mm	0.45 (± 0.03) mm	0.9 (± 0.06) mm	25 m	4262511622683
25CA623	Shrinking tube 2:1 transparent Φ 100 mm roll 25 m	100 mm	0.49 (± 0.03) mm	0.89 (± 0.06) mm	25 m	4262511622690