


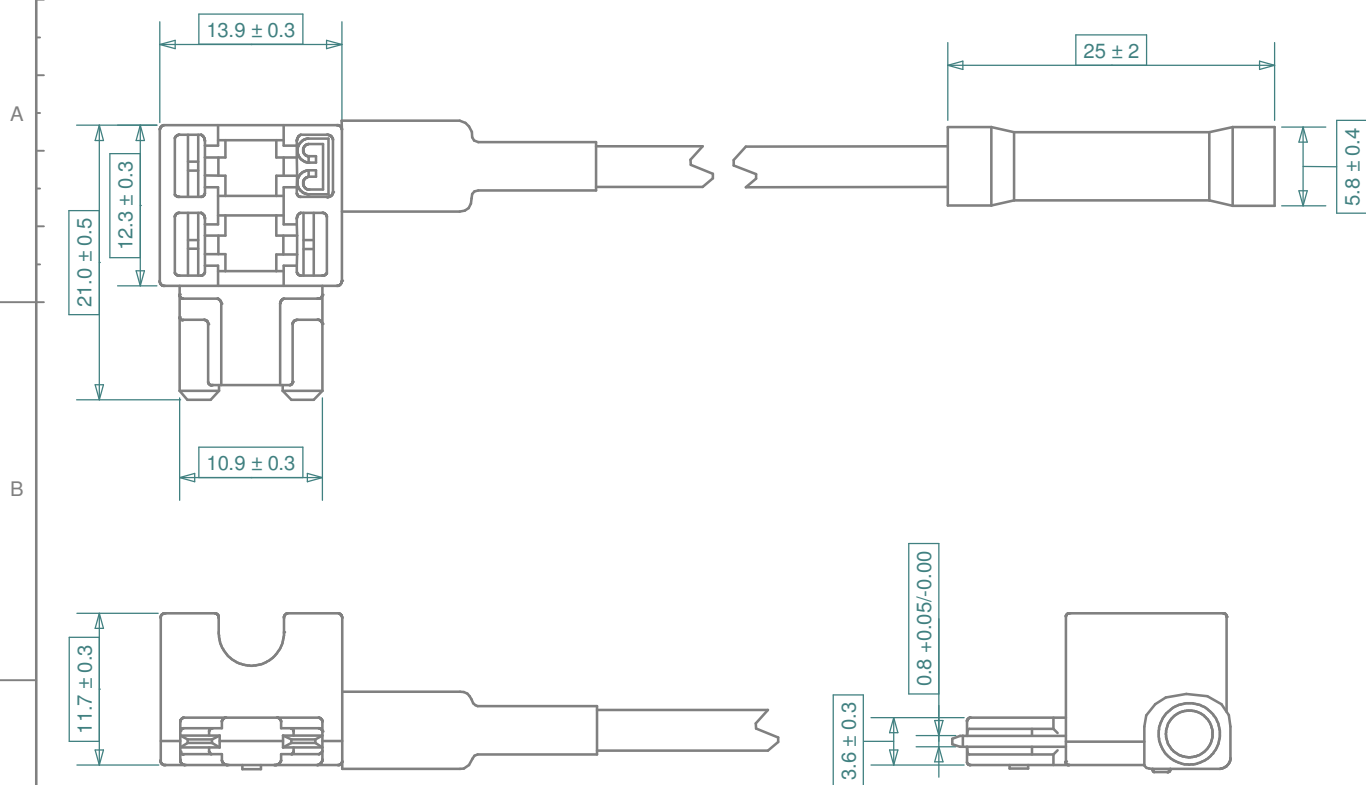


Notes and materials:

Body	Nylon PA66 UL 94V-0
Terminals	CuZn, Sn plated
Cable	120 ± 10mm, 16 AWG (1.3mm²) red wire
Connector	PVC butt connector, min. 15KG pull-out force
Current rating	Max. 10 Amp for additional circuit
Fuse series	FLP7000 series Low Profile miniOTO fuse, see table

FLP7000 series miniOTO Low Profile blade fuse ref. table:

Rating	Color	Volt	iMaXX Reference
[A]		[V]	
2	Gray	58	FLP7002
3	Violet	58	FLP7003
4	Pink	58	FLP7004
5	Tan	58	FLP7005
7.5	Brown	58	FLP7075
10	Red	58	FLP7010
15	Blue	58	FLP7015
20	Yellow	58	FLP7020
25	Natural	58	FLP7025
30	Green	58	FLP7030

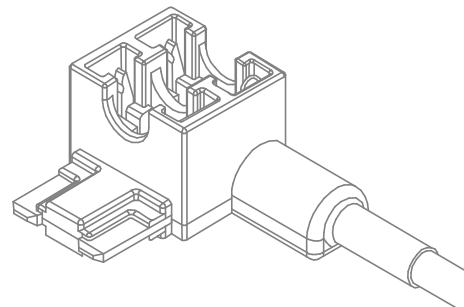

Revisions				Date	Appr.			
a	Date	Type	Drawn	05/13	GRH			
	05/17	updated notes and materials table	Checked	05/17	BE			
			Standards					
			Approved	05/17	AdH			
			Scale	not to scale		Title	HLP7400 series, Circuit+ LP miniOTO fuse	
			Projection	Tolerance ± 0.2 mm unless otherwise noted		Drawing type	schematic	
						Drawing number	HLP7400 drawing 1	
						Sheet	1 of 1	
						Layers / Sheet	0 1 2 6 9 11 Sheet 01	

