




DATASHEET

IP67 12 V/DC 70 dB Buzzer

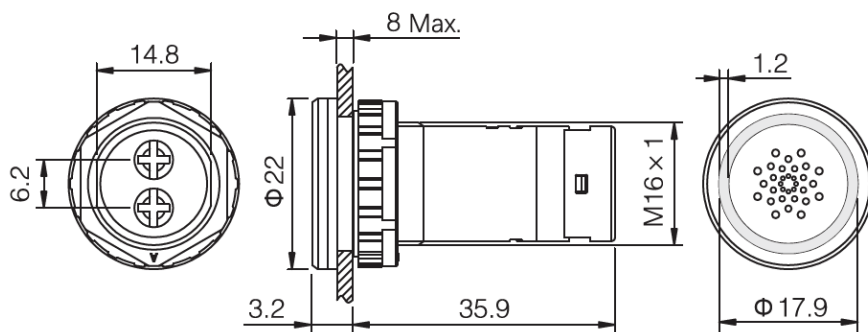

Dimensions in mm

Technical data

Item no.	3532760	3532761	3532762	3532763
Sound	Continuous	Discontinuous	Continuous	Discontinuous
Noise emission (max.)	70 dB (1m)	70 dB (1m)	70 dB (1m)	70 dB (1m)
Case colour (details)	Red	Red	Red	Red
Colours (LEDs)	--	--	Red	Red
LED alarm behaviour	--	--	Continuous on	Flashing
Operating voltage	12 V/DC	12 V/DC	12 V/DC	12 V/DC
Power frequency withstand voltage	1500 V/AC (50 Hz, 1 min)	1500 V/AC (50 Hz, 1 min)	1500 V/AC (50 Hz, 1 min)	1500 V/AC (50 Hz, 1 min)
Rated insulation voltage	250 V/AC	250 V/AC	250 V/AC	250 V/AC
Max. current consumption	18 mA	18 mA	28 mA	28 mA
Product size (Ø)	16/19 mm	16/19 mm	16/19 mm	16/19 mm
Flash rate (beeps)	42/min	42/min	42/min	42/min
Ingress protection	IP67	IP67	IP67	IP67
Material	PC/Stainless steel	PC/Stainless steel	PC/Stainless steel	PC/Stainless steel
Operating temperature	-20 to +50 °C	-20 to +50 °C	-20 to +50 °C	-20 to +50 °C
Brightness	≥20 cd/m²	≥20 cd/m²	≥20 cd/m²	≥20 cd/m²
Tightening torque	Nut: 0.6 N·m; Screw: 0.5 N·m	Nut: 0.6 N·m; Screw: 0.5 N·m	Nut: 0.6 N·m; Screw: 0.5 N·m	Nut: 0.6 N·m; Screw: 0.5 N·m
Wire	1 mm² (18 AWG) x1	1 mm² (18 AWG) x1	1 mm² (18 AWG) x1	1 mm² (18 AWG) x1
Weight (approx.)	10.3 g	10.3 g	10.3 g	10.3 g