
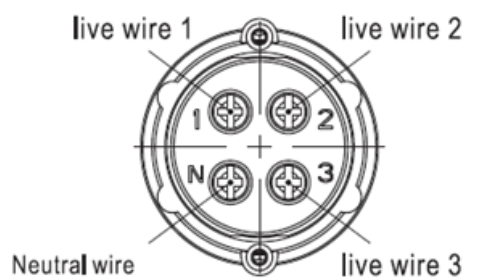
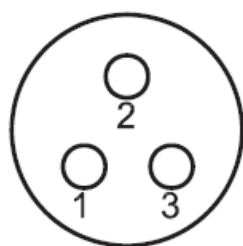


DATASHEET


3-Phase LED Indicator, IP67, Ø 30 mm

Item No. 3532764 RGY

Item No. 3532765 White

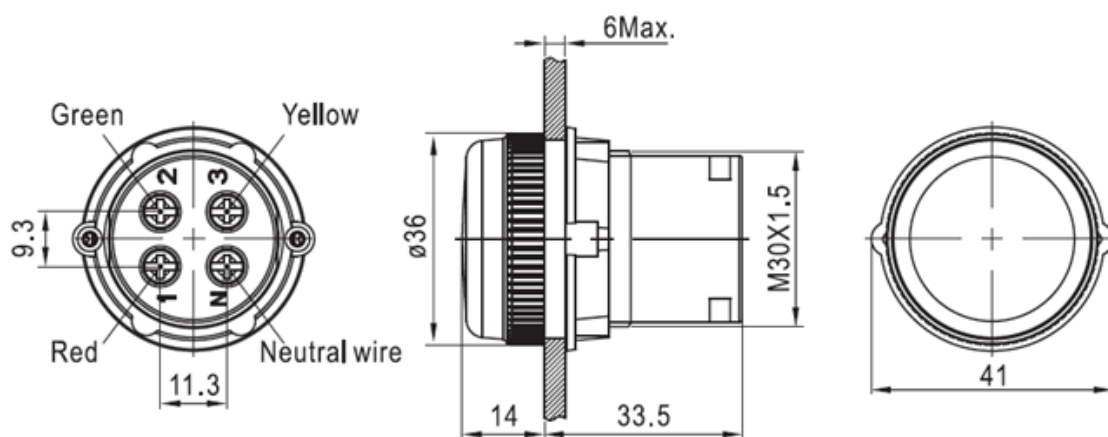


(It can also be used without connecting the neutral wire, but if two phases are missing, there will be no indication)

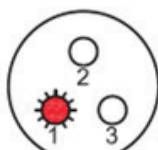


N + 1

Missing live wire 2 and 3

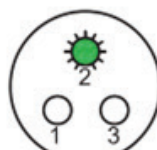


N + 2

Missing live wire 1 and 3

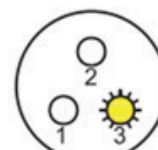

N + 3

Missing live wire 1 and 2

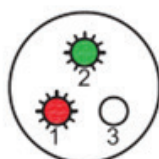


N + 1 + 2

Missing live wire 3




N + 1 + 3

Missing live wire 2

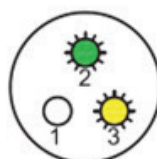

N + 2 + 3

Missing live wire 1

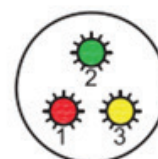

N + 1 + 2 + 3

Normal

Technical data

Ingress protection	IP67
Head shape	Round
Color	RGY (Item No. 3532764), White (Item No. 3532765)
Panel thickness	max. 6 mm
Panel cut out dimension	Ø 30 mm
Connection	Screw (wire within 1.5mm²)
Voltage between 2 phases	400 V ± 20 %
Voltage between phase and neutral	230 V ± 20 %
Operating and storage temperature	-20 to +55 °C
Head material	PC
Body material.....	PA