

VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For decades, our product range has been dynamically adapting to the constant changes in the industry.

We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.

NiMH RECHARGEABLE BATTERY HIGH DRAIN DISCHARGE 10A




TECHNICAL DATA

Item No.:	3533207	3533208	3533209	3533210
Type	NiMH (AA)			
Classification	Rechargeable			
Terminal type	Mignon HR6			
Nominal voltage	1.2 V			
Heavy metals	Lead(Pb)/Cadmium(Cd)/Mercury(Hg) are not detected(<MDL)			
Ambient temperature range	0 to +45 °C standard charge 10 to +45 °C fast charge -10 to +35 °C trickle charge -20 to +65 °C discharge temperature -20 to +35 °C storage temperature			
Life expectancy	≥500 cycles			
Capacity	1400 mAh	1400 mAh	2300 mAh	2300 mAh
Standard charge (16 hrs)	140 mAh	140 mA	230 mA	230 mA
Fast charge (1.1 hrs)	1400 mA	1400 mA	2300 mA	2300 mA

*For performance and safety, observe the operating / storage conditions.

DIMENSIONS

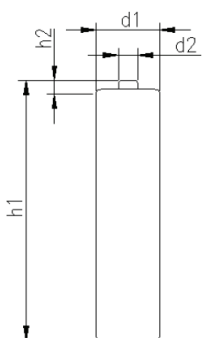

d1	max. 14.0 mm
h1	max. 48.6 mm