



07 P




With Tube

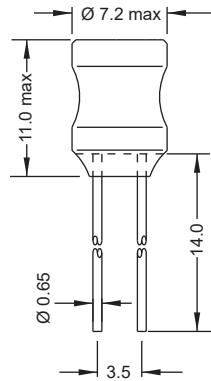

Loose / Box [-50]

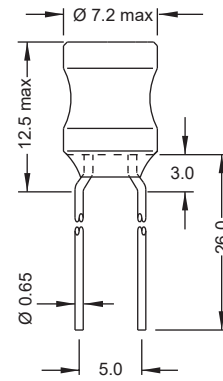

Taped / Reel [-51]

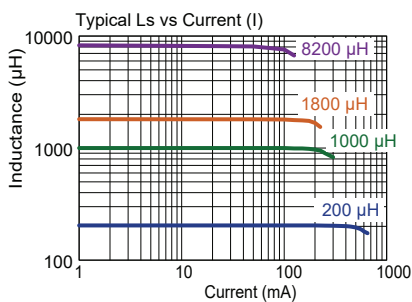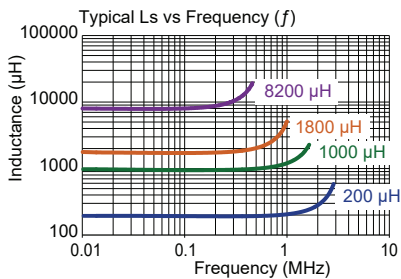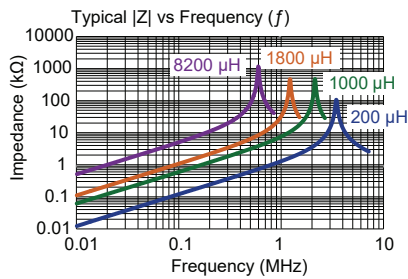

Part No	Inductance L (μH)	f _L (MHz)	Tol ± (%)	Q min	f _Q (MHz)	SRF min (MHz)	DCR max (Ω)	Rated DC Current (mA)
07P-201X-YY	200	0.02	5 ,10	80	0.796	3.20	0.90	450
07P-221X-YY	220	0.02	5 ,10	80	0.796	2.85	1.00	450
07P-681X-YY	680	0.02	5 ,10	80	0.796	2.00	3.10	250
07P-102X-YY	1000	0.02	5 ,10	115	0.796	1.80	3.55	220
07P-152X-YY	1500	0.02	5 ,10	115	0.252	1.05	5.20	155
07P-182X-YY	1800	0.02	5 ,10	115	0.252	1.05	5.70	150
07P-222X-YY	2200	0.02	5 ,10	115	0.252	1.00	6.50	150
07P-392X-YY	3900	0.02	5 ,10	100	0.252	0.70	12.00	100
07P-472X-YY	4700	0.02	5 ,10	100	0.252	0.65	13.50	100
07P-562X-YY	5600	0.02	5 ,10	100	0.252	0.60	15.00	80
07P-822X-YY	8200	0.02	5 ,10	100	0.252	0.45	27.35	80

Core Material: Ferrite

Revision date: 29 Jul 2022

SPQ:

Packaging Form	Loose / Box	Taped / Reel
Radial	500 [-50]	700 [-51]

Remarks: - Also available without tube.
- Also available with shorter leads.