

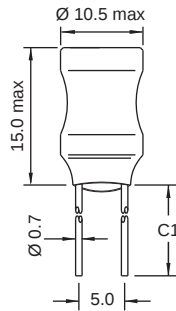
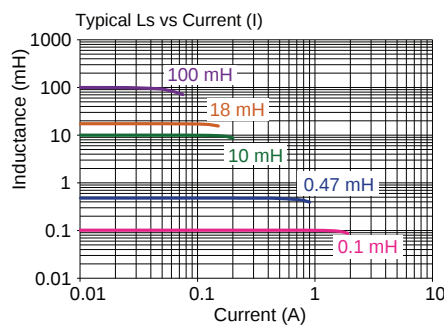


11 P

With Tube

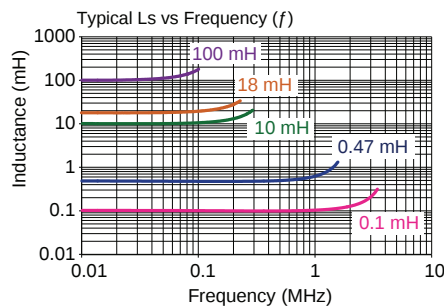

Packaging	C1
Loose / Box [-50]	10
Taped / Reel [-51]	25

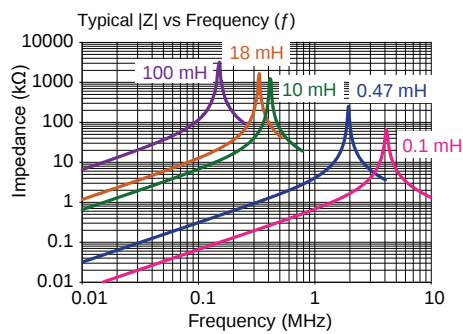

Part No	Inductance L (mH)	f _L (MHz)	Tol ± (%)	Q min	f _q (MHz)	SRF min (MHz)	DCR max (Ω)	Rated DC Current (A)	
								I _{sat} typ	I _{max}
11P-101K-YY	0.10	0.02	10	55	0.796	3.25	0.18	1.450	1.650
11P-221K-YY	0.22	0.02	10	45	0.796	2.30	0.32	1.000	1.250
11P-331K-YY	0.33	0.02	10	35	0.796	1.85	0.55	0.800	0.950
11P-471K-YY	0.47	0.02	10	30	0.796	1.55	0.65	0.650	0.900
11P-332X-YY	3.30	0.02	5,10	45	0.252	0.60	3.70	0.250	0.350
11P-103X-YY	10.0	0.02	5,10	95	0.079	0.35	13.5	0.140	0.185
11P-153X-YY	15.0	0.02	5,10	95	0.079	0.28	19.5	0.120	0.160
11P-183X-YY	18.0	0.02	5,10	95	0.079	0.28	21.0	0.095	0.145
11P-223X-YY	22.0	0.02	5,10	80	0.079	0.20	28.0	0.090	0.140
11P-333X-YY	33.0	0.02	5,10	80	0.079	0.20	41.0	0.080	0.110
11P-393X-YY	39.0	0.02	5,10	80	0.079	0.19	47.0	0.075	0.100
11P-473X-YY	47.0	0.02	5,10	75	0.079	0.18	54.0	0.055	0.090
11P-683X-YY	68.0	0.02	5,10	75	0.025	0.13	76.0	0.040	0.080
11P-823X-YY	82.0	0.02	5,10	75	0.025	0.13	99.0	0.035	0.075
11P-104X-YY	100	0.02	5,10	75	0.025	0.12	140	0.035	0.060
11P-124X-YY	120	0.02	5,10	65	0.025	0.09	174	0.020	0.055
11P-154X-YY	150	0.02	5,10	65	0.025	0.08	200	0.020	0.045

Core Material: Ferrite

Revision date: 12 Aug 2022

SPQ:	Packaging Form	Loose / Box	Taped / Reel
	Radial	250 [-50]	500 [-51]

Remarks: - Also available without tube.

- Also available with shorter leads.