

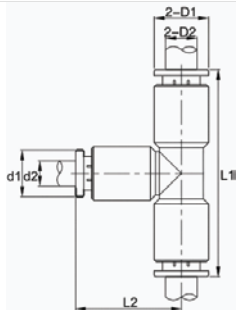
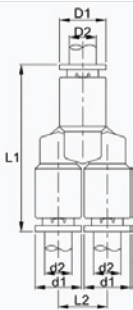
 
 
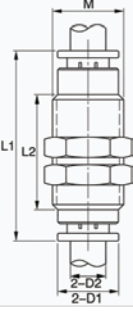
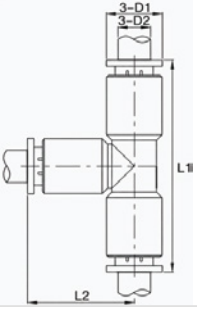
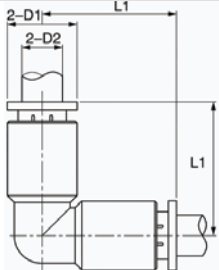
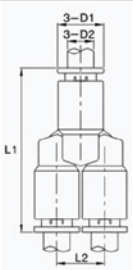
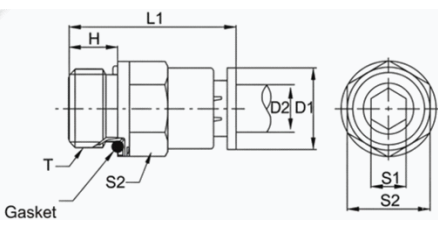
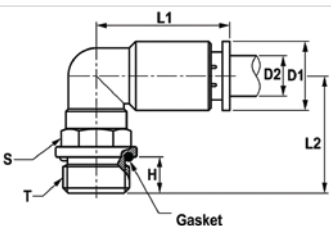
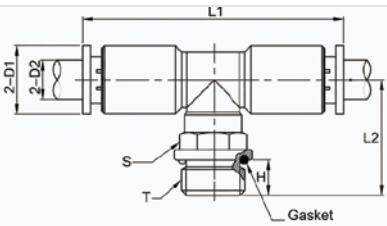
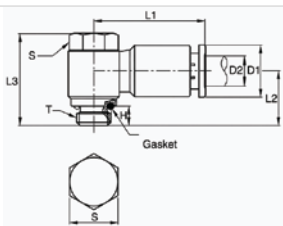
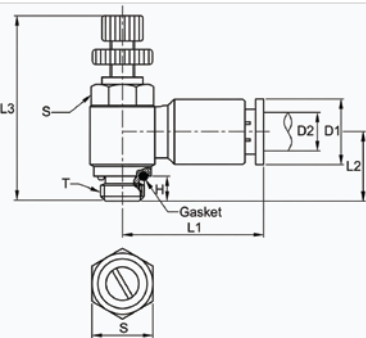


DATASHEET

Item No.:	Description	Model No.:	L1	L2	L3	H	S	S1	S2	T	d1 (ø)	D1 (ø)	d2 (ø)	D2 (ø)	M
3551367	Push-in fitting, brass tee reducer	MPEG8-6-8	44	20							12	14	6	8	
3551368	Push-in fitting, brass Y reducer	MPW8-6	38	13							12	14	6	8	
3551369	Brass union straight reducer	MPG8-6	35								12	14	6	8	
3551370	Straight through	MPU6	33									12		6	
3551371	Straight through	MPU8	36									14		8	
3551372	Brass bulkhead union straight	MPM6	33	19								12		6	M14
3551373	Brass bulkhead union straight	MPM8	36	21								14		8	M16
3551374	Brass union tee	MPE6	39	20								12		6	
3551375	Brass union tee	MPE8	44	22								14		8	
3551376	Brass Union Elbow	MPV6	20									12		6	
3551377	Brass Union Elbow	MPV8	22									14		8	
3551378	Y brass union	MPY6	37	13								12		6	
3551379	Y brass union	MPY8	41	15								14		8	
3551380	Metal male straight	MPC6-01G	20			5.5		4	12	G1/8		12		6	
3551381	Metal male straight	MPC6-02G	22			7		4	12	G1/4		12		6	
3551382	Metal male straight	MPC8-01G	25			5.5		5	14	G1/8		14		8	
3551383	Metal male straight	MPC8-02G	23			7		6	14	G1/4		14		8	
3551384	Metal male straight	MPC8-03G	20			7		6	14	G3/8		14		8	
3551385	Metal male elbow	MPL6-01G	20	18		5.5	12			G1/8		12		6	
3551386	Metal male elbow	MPL6-02G	20	21		7	12			G1/4		12		6	
3551387	Metal male elbow	MPL8-01G	22	19		5.5	12			G1/8		14		8	
3551388	Metal male elbow	MPL8-02G	22	23		7	12			G1/4		14		8	
3551389	Metal male elbow	MPL8-03G	22	23		7	12			G3/8		14		8	
3551390	Metal tee branch	MPB6-01G	39	21		5.5	12			G1/8		12		6	
3551391	Metal tee branch	MPB6-02G	39	24		7	12			G1/4		12		6	
3551392	Metal tee branch	MPB8-01G	44	23		5.5	12			G1/8		14		8	
3551393	Metal tee branch	MPB8-02G	44	27		7	12			G1/4		14		8	
3551394	Metal tee branch	MPB8-03G	44	27		7	12			G3/8		14		8	
3551395	Universal elbow	MPH6-01G	23	15	25.7	5.5	12			G1/8		12		6	
3551396	Universal elbow	MPH6-02G	25	19	31.4	7	15			G1/4		12		6	
3551397	Universal elbow	MPH8-01G	24	15	25.7	5.5	12			G1/8		14		8	
3551398	Universal elbow	MPH8-02G	27	19	31.4	7	15			G1/4		14		8	
3551399	Universal elbow	MPH8-03G	29	22	35.1	7	19			G3/8		14		8	
3551400	Brass elbow speed controller	MSL6-01G	23	16	37.5-45	4.7	12			G1/8		12		6	
3551401	Brass elbow speed controller	MSL6-02G	25	21	47-54.5	7.5	15			G1/4		12		6	
3551402	Brass elbow speed controller	MSL8-01G	24	15	37.5-45	4.7	12			G1/8		14		8	
3551403	Brass elbow speed controller	MSL8-02G	27	21	47-54.5	7.5	15			G1/4		14		8	
3551404	Brass elbow speed controller	MSL8-03G	29	25	51.5-58	8	19			G3/8		14		8	



DATASHEET

Item No.: 3551367 	Item No.: 3551368 	Item No.: 3551369 
Item No.: 3551370, 3551371 	Item No.: 3551372, 3551373 	Item No.: 3551374, 3551375 
Item No.: 3551376, 3551377 	Item No.: 3551378, 3551379 	Item No.: 3551380, 3551381, 3551382, 3551383, 3551384 
Item No.: 3551385, 3551386, 3551387, 3551388, 3551389 	Item No.: 3551390, 3551391, 3551392, 3551393, 3551394 	Item No.: 3551395, 3551396, 3551397, 3551398, 3551399 
Item No.: 3551400, 3551401, 3551402, 3551403, 3551404 		



DATASHEET

Item No.: 3551367 	Item No.: 3551368 	Item No.: 3551369 
Item No.: 3551370, 3551371 	Item No.: 3551372, 3551373 	Item No.: 3551374, 3551375 
Item No.: 3551376, 3551377 	Item No.: 3551378, 3551379 	Item No.: 3551380, 3551381, 3551382, 3551383, 3551384 
Item No.: 3551385, 3551386, 3551387, 3551388, 3551389 	Item No.: 3551390, 3551391, 3551392, 3551393, 3551394 	Item No.: 3551395, 3551396, 3551397, 3551398, 3551399 
Item No.: 3551400, 3551401, 3551402, 3551403, 3551404 		