




DATASHEET


Solenoid Valve



Item No. 3552920, 3552921

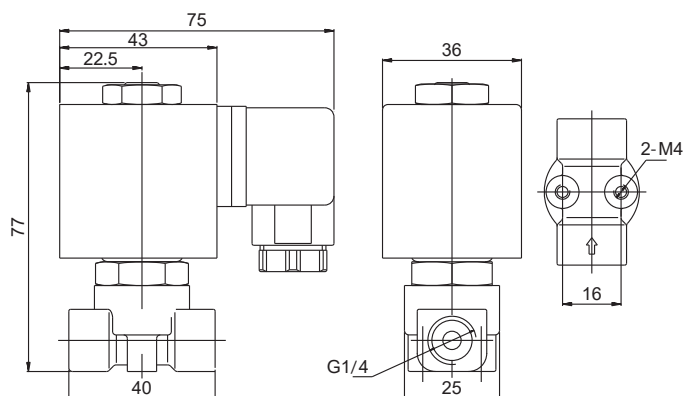

Item No. 3552923

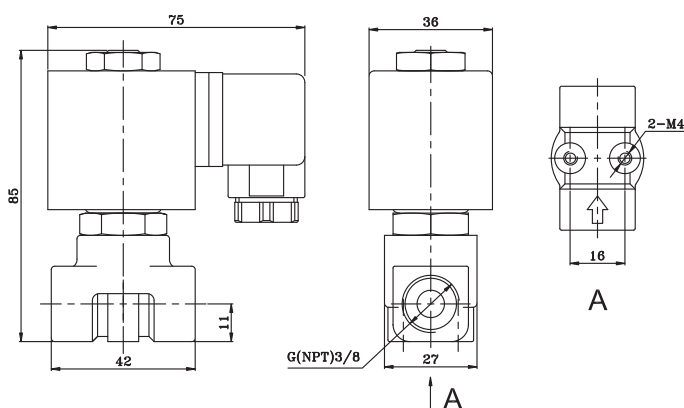

Item No.: 3552920	Item No.: 3552921	Item No.: 3552922
Model No.: TC-YCSM31-1/8G-AC230	Model No.: TC-YCSM31-1/4G-AC230	Model No.: TC-YCSM31-3/8G-AC230
G1/8 2/2 Way solenoid valve AC 230 V	G1/4 2/2 Way solenoid valve AC 230 V	G3/8 2/2 Way solenoid valve AC 230 V
2 ports/2 position	2 ports/2 position	2 ports/2 position
Normally closed (NC)	Normally closed (NC)	Normally closed (NC)
Port size: G1/8	Port size: G1/4	Port size: G3/8
DN 6	DN 8	DN 10
230 V/AC	230 V/AC	230 V/AC
Fluid: Air, Water, Oil	Fluid: Air, Water, Oil	Fluid: Air, Water, Oil
Acting type: Direct Lifting	Acting type: Direct Lifting	Acting type: Direct Lifting
Working pressure: 0 - 10 Bar	Working pressure: 0 - 10 Bar	Working pressure: 0 - 10 Bar
Orifice: 1.5 mm	Orifice: 2.5 mm	Orifice: 4 mm
Kv: 0.095	Kv: 0.156	Kv: 0.432
Temperature: -10 - 80°C	Temperature: -10 - 80°C	Temperature: -10 - 80°C
Seal: NBR	Seal: NBR	Seal: NBR
Body material: Brass	Body material: Brass	Body material: Brass