

0170: Adjustable wrench extra light with thin jaws



The + product :

Extra-light: 30% less weight compared with a traditional adjustable wrench.

Thin jaws: to adapt to the thinnest nuts.

Wide opening: the jaw opens wider than wrenches with equivalent length.

Description

Extra light adjustable wrench for user comfort. This optimal design reduces weight by up to -30% compared with a traditional wrench and -48% compared with a technical wrench, while maintaining excellent strength thanks to high grade steel.

Thin jaws ensure optimal access, up to 50% thinner than standard wrenches with similar opening potential. Homogeneous thickness over the full length of the jaws, which is ideal for fitting and removing locknut systems.

With its wide opening jaw it replaces two wrenches (6"-8" for reference 017020, 8"-10" for reference 017021, etc.)


Triple coating of nickel and chrome provides high corrosion resistance.

Handle with anti-slip coating for better grip.

Short and smooth mobile jaw rod, for use in small spaces.

Fixed jaw graded in mm and inch for adjustment before use.

Complies with ISO 6787:2001 and ASME B107.100-2010 standards.

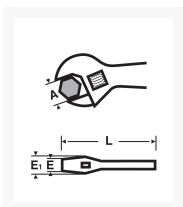

References

Sku	Accross flats A mm	Accross flats A"	E mm	E1 mm	L mm	L "	kg
017020	24	15/16"	4	10,8	161	6	0,115
017021	30	1.3/16"	5	14,0	207	8	0,210
017022	36	1.7/16"	6	15,5	259	10	0,345
017023	46	1.13/16"	8	19,0	311	12	0,600

