

0170 : Extra-Wide Opening Adjustable Wrench



The + product :

Practical:

One wrench instead of several, saves weight and space.

For confined spaces:

Thin noses and flush moving jaw when open.

2 additional extra-wide opening versions:

Classical or with thin jaws for confined locations.

Description

Extra-wide opening, sheathed adjustable wrench, ideal for working on copper and brass in plumbing, air-conditioning, refrigeration, maintenance and heating applications.

With its wide-opening jaw and torsional strength, it replaces 3 wrenches (6"-8"-10" for ref. 017045/017047, 8"-10"-12" for ref. 017050/017052, 10"-12"-15" for ref. 017055).


Non-slip sheathed handle for a better grip.

Extra-wide opening adjustable wrench with extra-thin jaws (ref. 017047 and 017052) adapted to the thinnest nuts.

Ideal for assembly and disassembly of locknut systems.

Maximum access thanks to nose 50% slimmer than standard wrenches with similar opening, and even thickness over the entire nose length.

Complies with ISO 6787:2001 and ASME B107.100-2010 standards.

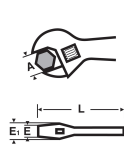

References

Sku	Accross flats A mm	Accross flats A"	E mm	E1 mm	L mm	L "	kg
017045	34	1.1/4"	6	14	175	6	0,210

Sku	Accross flats A mm	Accross flats A"	E mm	E1 mm	L mm	L "	kg
017047	34	1.1/4"	4	14	175	6	0,210
017050	39	1.1/2"	6	14	215	8	0,350
017052	39	1.1/2"	4	14	215	8	0,350
017055	53	2.1/16"	6	16	250	10	0,640

