

VOLTCRAFT


VOLTCRAFT - RELIABLE AND PRECISE. SINCE 1982.

For more than 40 years, our product range has been dynamically adapting to the constant changes in the industry. We commit to offering first-class quality to our customers while delivering an excellent cost-performance ratio. This philosophy remains the cornerstone of Voltcraft's success.

MSL-530 CATIII 1000 V TEST LEADS SET



Item no. 3353222

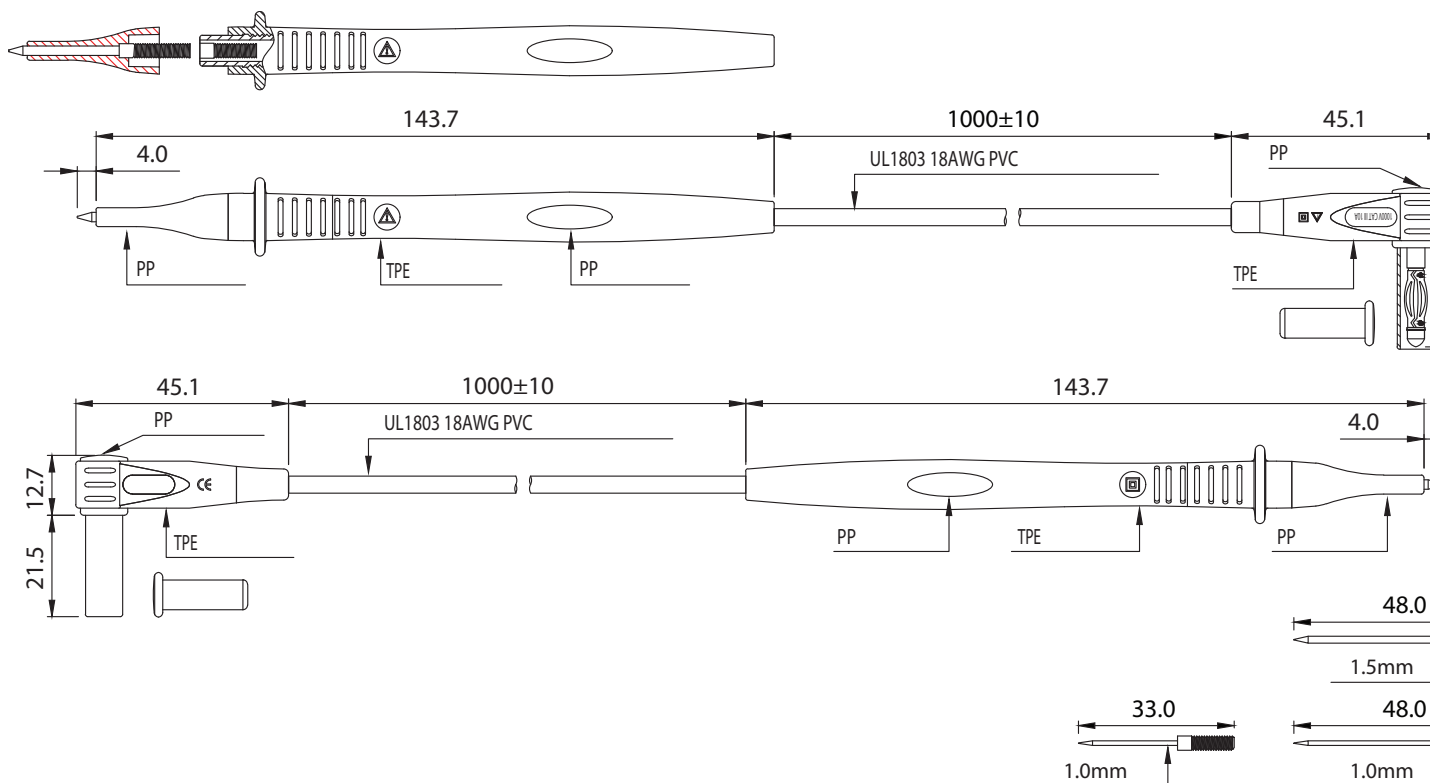

FEATURES

CAT III 1000V 10A test lead // 1 x black + 1 x red = one unit // changeable probe tip with different dimensional metal tips

TECHNICAL DATA

- CAT III 1000V 10A
- 4 mm stackable, shrouded right angle plug with protective header on the other and double injection to win the utmost safety & good holding
- cable length: 1.0 m
- Conductor size: 18 AWG
- Type of contact: Probe pin
- Cable type: UL1803 18AWG PVC
- Operating temperature: -10 to 85 °C
- Operating humidity: 25 to 85 % RH
- Storage temperature: -20 to 70 °C
- Storage humidity: 25 to 85 % RH
- Length: 1189 mm
- 3x pairs of insulated tips (screw in):
 - 1) diameter 1.0mm, length 33mm
 - 2) diameter 1.0mm, length 48mm
 - 3) diameter 1.5mm, length 48mm

PACKAGE CONTENTS

Red + black test lead x 1 pair // changeable tips x 3 pairs



This is a publication by Conrad Electronic SE, Klaus-Conrad-Str. 1, D-92240 Hirschau (www.conrad.com). All rights including translation reserved. Reproduction by any method, e.g. photocopy, microfilming, or the capture in electronic data processing systems require the prior written approval by the editor. Reprinting, also in part, is prohibited. This publication represents the technical status at the time of printing.

Copyright 2026 by Conrad Electronic SE. *3553222_V1_1225_02_ds_dh_en