

Product Datasheet model uvex ultrashield 9122 415

**UVEX ARBEITSSCHUTZ GMBH, Würzburger Str. 181-189,
D-90766 Fürth**

1. Product Characteristics

- extremely sporty safety spectacles, ideal for fashion-conscious wearers
- very large lens design for an unrestricted, wide field of vision and increased safety
- soft-grip temple ends provide a comfortable, secure fit without pressure
- soft, adjustable nose piece makes it possible to adjust the glasses to the wearer and ensures a comfortable, non-slip, pressure-free fit
- robust polycarbonate lens with UV400 – 100% protection against dangerous UV radiation up to 400 nm

2. Technical Details Body

Frame

Material	PC, TPR
Colour	white, black

Marking

Applicable EN ISO norm	16321
Manufacturer 's ID code	W
Impact resistance	C (45 m/s)
Tested under extreme temperatures	T
Conformity symbol	CE

3. Technical Details Lens

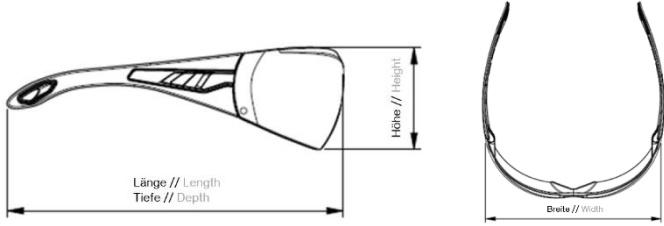
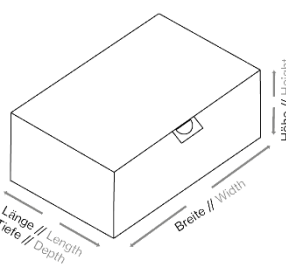
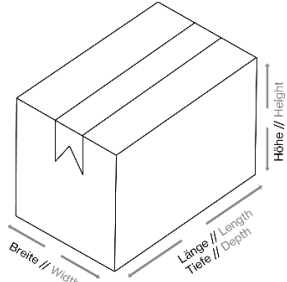
Material	PC
Thickness	2.0 mm at PD
Coating	scratch resistant, anti-fog
Tint	clear
Features tint	Signal colour recognition
UV protection	UV400

Marking

Manufacturer 's ID code	W
Filter	UL
Tinting level	1.2
Impact resistance	C (45 m/s)
Tested under extreme temperatures	T
Optical class	1
Scratch resistance	K
Antifog	N
Conformity symbol	CE
Factory symbol	

4. Logistical Information

Product

Weight	33g		
Dimensions (L x W x H) in approx. mm	 picture only for reference		
	172 x 151 x 57		
	Packing unit 1	Packing unit 2	Packing unit 3
EAN Code	4066853051930	4066853051947	4066853051954
Quantity in pcs.	1	8	128
Dimensions (L x W x H) in approx. mm	 picture only for reference		
	127 x 267 x 60	185 x 290 x 97	600 x 400 x 400
Net weight in approx. g	33	164	4,224
Gross weight in approx. g	49	495	8,056
Country of Origin	Taiwan		

5. Miscellaneous

Standards	EN ISO 16321-1
PPE Category	Category II