



D-C2500H Specifications

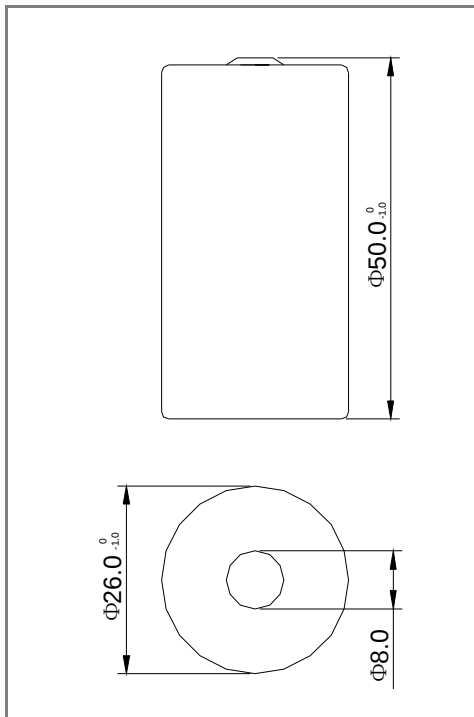


Nominal Capacity	2500mAh
Nominal Voltage	1.2V
Internal Impedance (at 1000Hz)	< 10mΩ
Charge	
Standard Charge (1C)	250mA x 15h
Trickle Charge (0.05C)	125mA x 1.2h
Discharge Cut-off Voltage	1.0V
Max Dimension (with tube)	
Diameter	26.0mm
Height	50.0mm
Weight	70 g
Ambient Temperature	
Standard charge	0 ~ 60°C
Trickle charge	0 ~ 60°C
Discharge	-20 ~ 70°C
Storage	-20 ~ 45°C


Standard charge characteristics

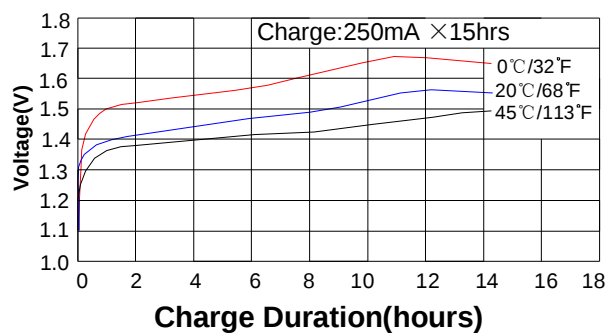

Trickle charge characteristics

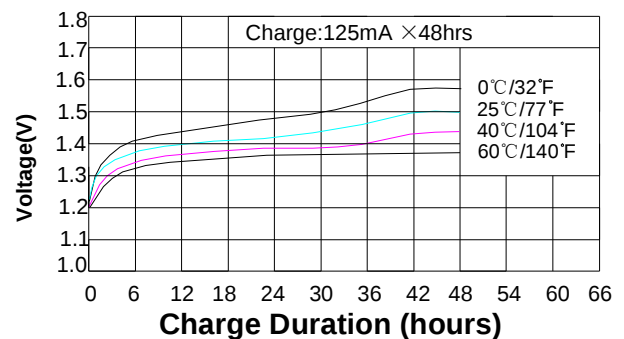

Discharge characteristics

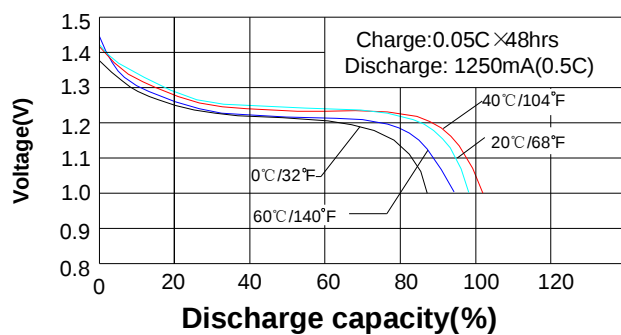

Charge efficiency

