


Door/Window Magnetic Sensor

Item no. 3553836

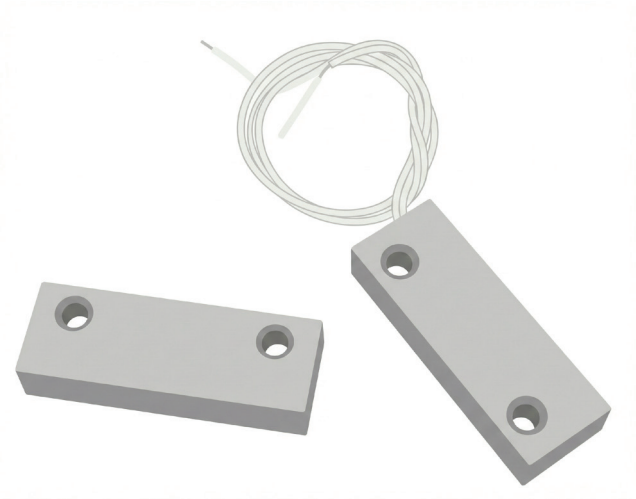

Delivery content

- Door/ window sensor
- 4x Screws
- Data sheet

Important

- Do not use the product for safety-critical applications
- Do not let children play with the product
- Do not install the product near heat sources
- Do not place the product under any mechanical stress
- Keep away the product from magnetic sources that can cause interference
- Keep away the product from water, moisture and direct sunlight

Disposal



This symbol must appear on any electrical and electronic equipment placed on the EU market. This symbol indicates that this device should not be disposed of as unsorted municipal waste at the end of its service life.

Owners of WEEE (Waste from Electrical and Electronic Equipment) shall dispose of it separately from unsorted municipal waste. Spent batteries and accumulators, which are not enclosed by the WEEE, as well as lamps that can be removed from the WEEE in a non-destructive manner, must be removed by end users from the WEEE in a non-destructive manner before it is handed over to a collection point.

Distributors of electrical and electronic equipment are legally obliged to provide free take-back of waste. Conrad provides the following return options **free of charge** (more details on our website):

- in our Conrad offices
- at the Conrad collection points
- at the collection points of public waste management authorities or the collection points set up by manufacturers or distributors within the meaning of the ElektroG


End users are responsible for deleting personal data from the WEEE to be disposed of.

It should be noted that different obligations about the return or recycling of WEEE may apply in countries outside of Germany.


Technical data

Housing materials	Zinc-alloy
Contact type	NC (Normally Closed)
Operating voltage	0 - 24 V/DC
Max. rated power	10 W
Cable length	approx 25 cm
Separation distance	25 - 35 mm
Operating temperature/humidity	-10 to +45 °C; 80 % RH
Storage temperature/humidity	-10 to +45 °C; 80 % RH
Dimensions (L × W × H)	49 × 20 × 9.6 mm
Weight	50 g

Dimensions

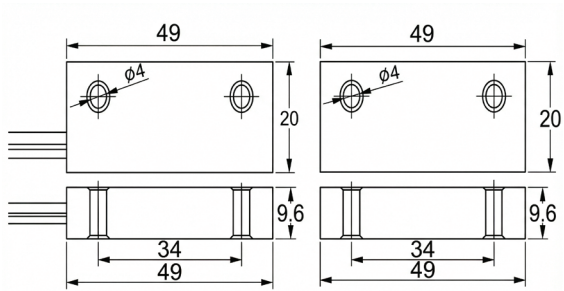

All dimensions in mm

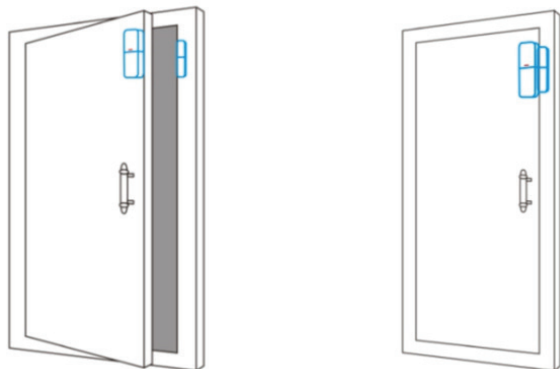

Use screws or double-sided tape to mount.