




DATASHEET

Direct Acting Valves


Direct Acting Valves

Item No.:	3553838	3553839	3553840	3553841	3553842	3553843	3553844	3553845
Connection port	9.728 mm (G 1/8")		13.16 mm (G 1/4")		16.66 mm (G 3/8")		20.96 mm (G 1/2")	
Default state	NC	NC	NC	NC	NC	NC	NC	NC
Operating voltage	24 V/DC	230 V/AC	24 V/DC	230 V/AC	24 V/DC	230 V/AC	24 V/DC	230 V/AC
Water Flow, Kv	0.41 m ³ /h							
Vapor Flow, QNn	494.1 L/min							
Max. pressure	16 bar							
Max. media temperature	160 °C							
Valve material	Brass							
On time setting	-							
Off time setting	-							
Protection level	IP65							
Working temperature	-20 to +60 °C							

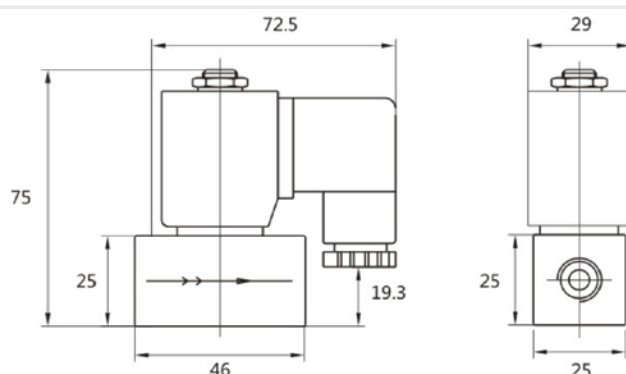


Direct Acting Valves with Mechanical Timer


Item No.:	3553846	3553847	3553848	3553849	3553850	3553851	3553852	3553853
Connection port	9.728 mm (G 1/8")		13.16 mm (G 1/4")		16.66mm (G 3/8")		20.96 mm (G 1/2")	
Default state	NC	NC	NC	NC	NC	NC	NC	NC
Operating voltage	24 V/DC	230 V/AC	24 V/DC	230 V/AC	24 V/DC	230 V/AC	24 V/DC	230 V/AC
Water Flow, Kv	0.41 m ³ /h							
Vapor Flow, QNn	494.1 L/min							
Max. pressure	16 bar							
Max. media temperature	160 °C							
Valve material	Brass							
On time setting	0.5 - 10 s							
Off time setting	0.5 - 45 min							
Protection level	IP65							
Working temperature	-20 to +60 °C							

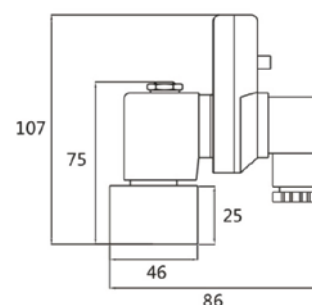

Item No.:	3553857	3553858
Connection port	20.96 mm (G 1/2")	
Default state	NC	NC
Operating voltage	24 V/DC	230 V/AC
Water Flow, Kv	0.26 m³/h	
Vapor Flow, QNn	322.8 L/min	
Max. pressure	16 bar	
Max. media temperature	160 °C	
Valve material		
On time setting	0.5 - 10 s	
Off time setting	0.5 - 45 min	
Protection level	IP65	
Working temperature	0 to +80 °C	

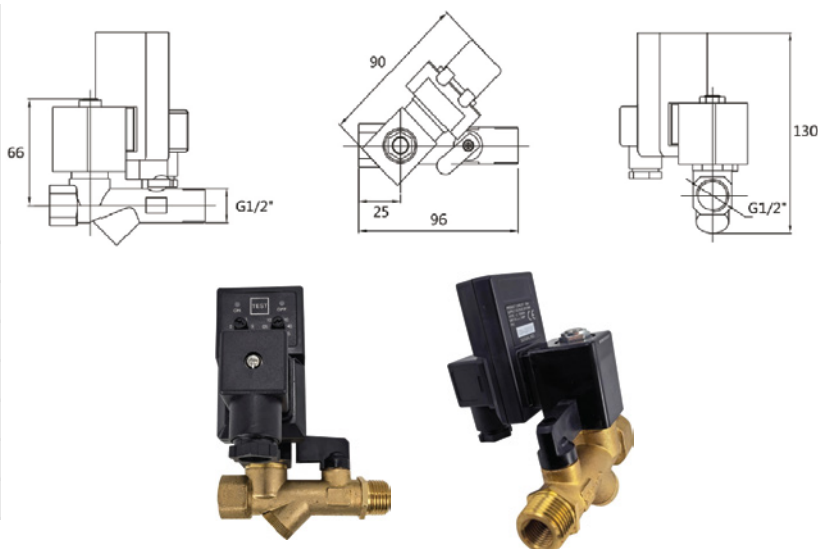

Item No.:	3553854	3553855	3553856
Port size (p)	13.16 mm (G 1/4")	16.66 mm (G 3/8")	20.96 mm (G 1/2")
Max. pressure	16 bar		
Max. media temp.	160 °C		
Working temperature	-5 to +80 °C		

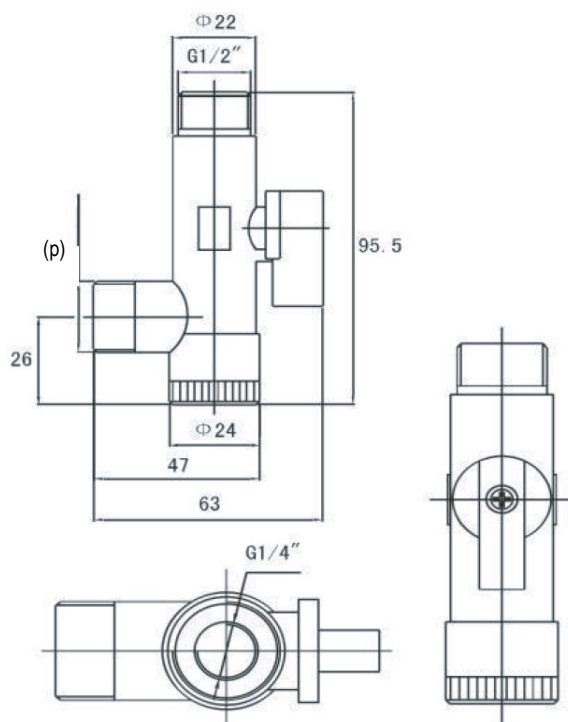

1