


DATASHEET

MP-50 4 mm Straight Banana Plug - Gold Plated

Item No. 3558197

Overview

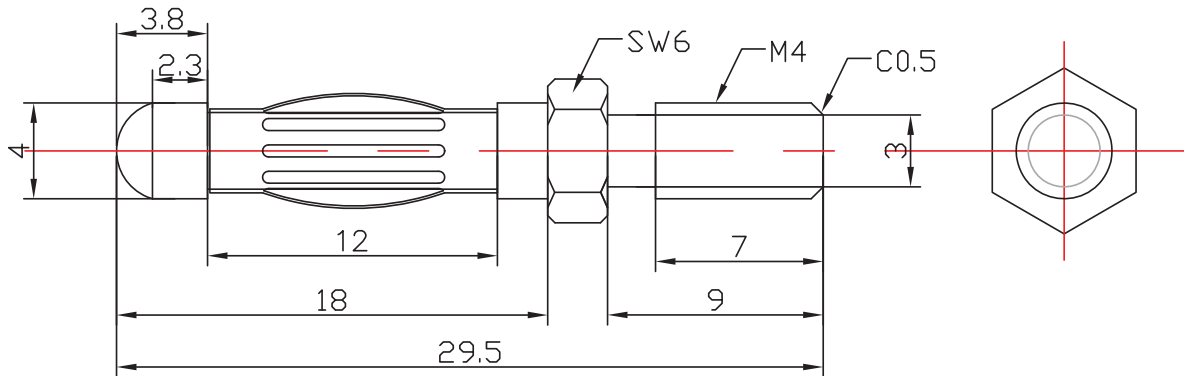

All measurements in mm

Technical data

Rated current.....	max. 50 A
Contact resistance.....	100 mΩ
Plug	4mm straight banana plug
Connection	Banana plug/rear threaded stud, uninsulated
Material.....	Brass, gold plated
Product dimensions (L x Ø)	29.5 x Ø 4 mm
Operating temperature	-20 to +65 °C
Color	Gold

