



23.8" Hybri Monitor (EB241CJB)

ecoVISION™  **ECO-FRIENDLY DISPLAY** Experts In Display **HDMI™** HIGH-DEFINITION MULTIMEDIA INTERFACE



Features

- Harness natural light with ecoVISION™ Display to protect your eyes from harmful blue light. Enjoy a flicker-free, anti-glare, and paper-like viewing experience designed for lasting comfort and superior eye care.
- Beside the Standard scene mode, We also provide four eye-protective modes: Adp.Vivid, Eye Care, Indoor, and Program to enhance your viewing experience.
- 75Hz high refresh rate ensures smooth text scrolling and video streaming without ghosting.
- Sunlight readable; Anti-glare display
- Colorful content: 16.7 million display colors
- This display features an ambient light sensor that adjusts brightness based on ambient conditions, providing users with optimal visibility in any environment.
- Versatile connectivity includes HDMI, DP, and Type-C ports
- This monitor features a USB Type-C connector with up to 65W power delivery with compatible devices. You can power your device, transfer data, and transmit display signals with a single cable.
- Ergonomic adjustable stand enables users to tilt, pivot, and swivel to different angles or adjust its height for optimal comfort
- Easy to install on a desk or wall with its 100x100 VESA mounting interface.
- Green & Healthy Design, Low Power Consumption.

 23.8"	23.8 Inch / 60.45 cm	 Anti-Glare	Anti-Glare
 1920 x 1080	Resolution 1920 x 1080	 Eye Care	Eye-Friendly Viewing Experience
 75Hz	75Hz Refresh Rate	 BL Zero Blue Light	Zero Blue Light (sunlight reflect mode)
 16.7M	16.7M Display Colors	 Sunlight Readable	Sunlight Readable
 Versatile I/O Ports	Versatile I/O Ports	 65W Power Delivery	Type-C 65W Power Delivery
 Ergo-Stand	Ergo-Stand VESA 100 x 100	 Light Sensor	Ambient Light Sensor

Technical Specifications

Name / Part No.	23.8" Hybri Monitor EB241CJB	VESA Wall Mount	100 x 100 mm (4 holes)
Screen Size	60.45cm / 23.8-inch	Front Control	Six keys on the bezel
Resolution (H x V)	1920 x 1080, 16:9 Aspect Ratio	I/O Ports	HDMI (v2.0)*1 DP (v1.4)*1 * Type-C(with 65W Power Delivery)*1 USB-HUB (USB-A *2, USB-B *1)
Display Type	ecoVision™ Display TN, Transflective	Operating Condition	Temperature 5° C ~ 35° C; Humidity 20% ~ 85%, non-condensing
Display Colors	16.7M Colors	Indicator Light	Power on: Blue ; Power Saving: Amber
Response Time	6ms(Typical)	Output	Speaker 2W *2, Earphone *1
Refresh Rate	75 Hz	Accessory	Power Adaptor, Power Cord (1.5M), HDMI Cable (1.5m) Type-C Cable (1.8m), User Manual (e-file), Quick Start guide(Paper)
Viewing Angle (CR>10)	120° (H) / 110° (V)	Certification	CE, RoHS, HDMI
Color Gamut	50.4% NCS	EAN Code	4711404025020
Contrast (Typical)	20:1	Features	ecoVISION™ Display; Paper-like Display; Sunlight Readable; Eye-friendly Reading Experience; 75Hz High Refresh Rate; Ambient Light Sensor for Optimal Screen Brightness
Brightness	180 nits		
Pixel Pitch	0.2745 (H) x 0.2745 (V) m		
Cover Glass Surface Treatment	AGLR (Anti Glare Low Reflection)		
Ambient Light Sensor	Yes		
Preset Mode	Standard / Adp.Vivid / Eye care / Indoor / Program		
Color Temp	WARM, NATURE, COOL, User Mode		
Speakers	Yes, 2 Watts*2		
Power Voltage	24V/5A		
Power Consumption	On: 5.2W (RLCD mode) ~ 17.16W; Stand By: 0.46W; Off: 0.29W		
Kensington Lock	Yes		
Quick Release Stand	Yes		
Rotate	±90°		
Swivel	Left: 80° ~ Right: 80°		
Tilt (down/up)	-5° ~ 20°		
Height Adjustment Stand	130 mm		
Product Dimensions	538mm (W) x 371~501 mm (H) x 225mm (D)		
Packing Dimensions	664mm (W) x 467mm (H) x 214mm (D)		
Net Weight	4.9 KG		
Gross Weight	8.6 KG		

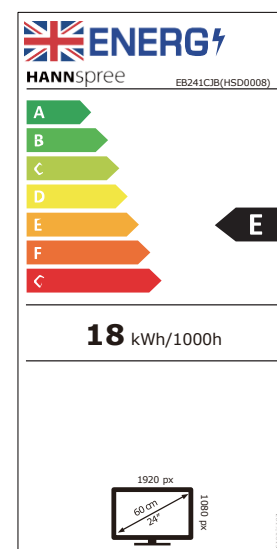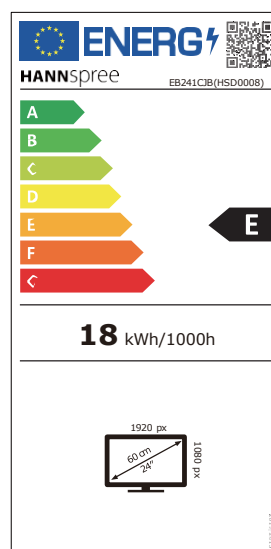

* The standby mode via Type-C may be limited on some Mac computers.

EAN



P/N: EB241CJB

23.8" Hybri Monitor

Dimensions & Connectors

