

Model No.: **GP910A**


 

| NO MERCURY ADDED          |                                                         |
|---------------------------|---------------------------------------------------------|
| <b>Description</b>        | : Mercury Free Alkaline Manganese Battery, N Size       |
| <b>Chemical System</b>    | : Alkaline Manganese                                    |
| <b>Nominal Voltage</b>    | : 1.5 Volts                                             |
| <b>Nominal Dimensions</b> | : $\varnothing 12.0$ mm x 30.2 mm                       |
| <b>Terminals</b>          | : Protruded positive (+) and flat negative (-) contacts |
| <b>Jacket</b>             | : Foil jacket                                           |
| <b>Applications</b>       | : Hearing aid, pager, etc.                              |
| <b>Warranty Period</b>    | : 36 months                                             |
| <b>Average Weight</b>     | : 9g                                                    |

### Cross References:

| GP   | JIS | IEC | Energizer | Duracell/ |
|------|-----|-----|-----------|-----------|
| 910A | LR1 | LR1 | E90       | MN9100    |

### Typical Service Life:

| Discharge Resistance | Discharge Condition | End Point Voltage | Service Life |
|----------------------|---------------------|-------------------|--------------|
| 20 Ohms              | 24 Hrs/ Day         | 0.9V              | 11.8 Hrs     |

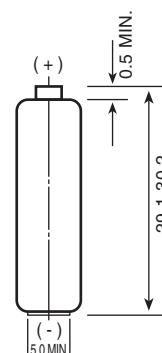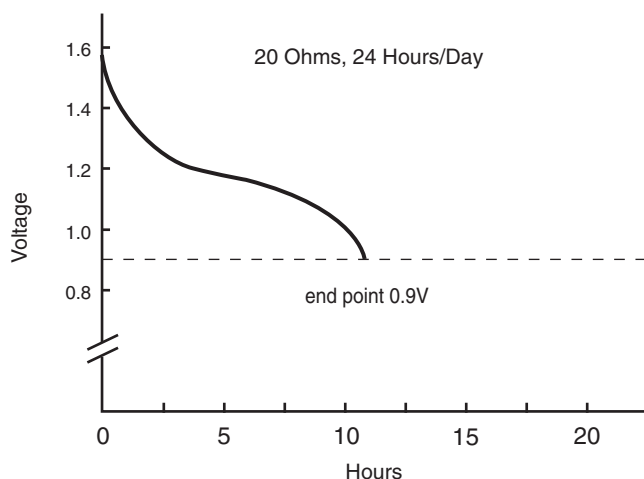

Unit : mm

[www.gpbatteries.com](http://www.gpbatteries.com)

Manufacturer reserves the right to alter or amend the design, model and specification without prior notice.  
Copyright© GPI International Ltd. - All rights reserved

Member  
Gold Peak Group

11100110294

The information (subject to change without prior notice) contained in this document is for reference only and should not be used as a basis for product guarantee or warranty. For applications other than those described here, please consult your nearest GP Sales and Marketing Office or Distributors.