
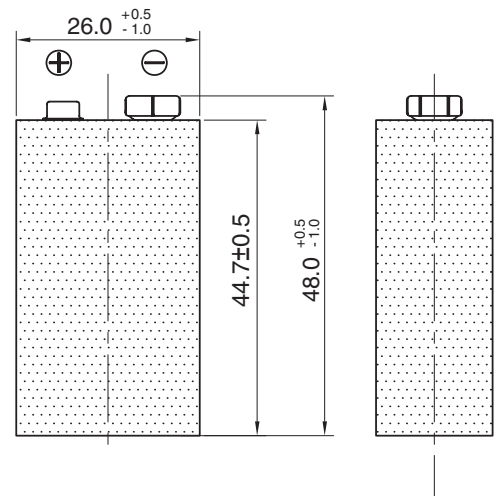




Description	: Lithium Battery, 9V Size
Chemical System	: Lithium Manganese Dioxide
Nominal Voltage	: Volts
Nominal Capacity	: 800mAh @ 10mA to 5.4V at 23°C
Dimensions	: 26(L) x 16.5(W) x 48(H)mm
Terminals	: Standard snap fastener stud(+) and socket(-)
Shelf Life	: up to 10 years
Average Weight	: App. 34g
Max. Constant Current	: 1000mA
Max. Pulse Current	: 2500mA
Application	: Smoke detectors, security devices, medical equipment, carbon monoxide alarms, explosion gas alarms, meters (gas/electric/water), metal detectors, wireless transmitters, electronic toll collection system, etc.
Operating temperature	: -40°C to +60°C
UL Standard	: UL1642 (File no. MH46184) UL2054 (File no. MH25972)
IEC Standard	: IEC60086-4
UN Standard	: UN38.3

Model No.: **GPCR-V9**

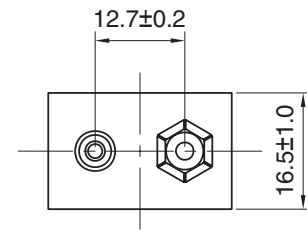

Cross References:

ANSI	GP	Energizer	Ultralife
1604LC	CR-V9	L522	U9VL

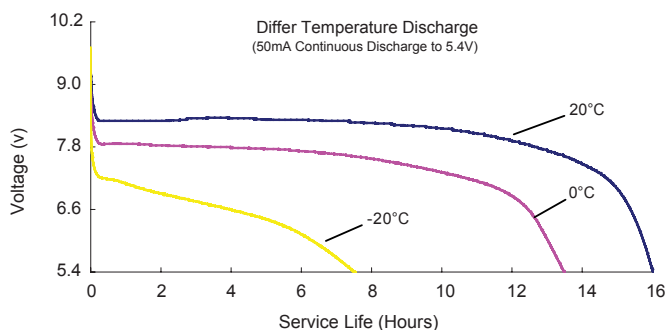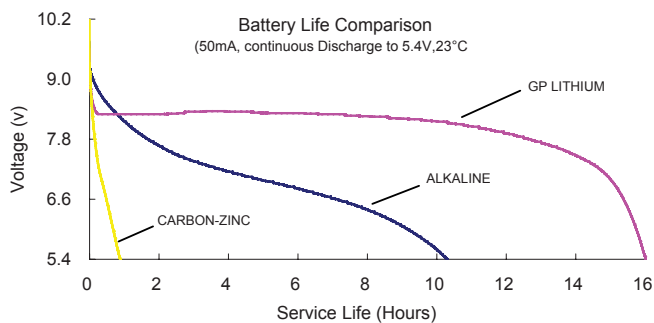

www.gpbatteries.com

Label Area

Unit : mm

The information (subject to change without prior notice) contained in this document is for reference only and should not be used as a basis for product guarantee or warranty. For applications other than those described here, please consult your nearest GP Sales and Marketing Office or Distributors.