


Model No.: GPCR123A Pro





Description	: Consumer Lithium Battery, CR123A Pro
Chemical System	: Lithium Manganese Dioxide
Nominal Voltage	: 3.0 Volts
Nominal Capacity	: 1500mAh @ 10mA to 2.0V at 23°C
Dimensions	: Ø17 mm x 34.5 mm
Terminals	: Flat, Recessed Negative Terminal
Shelf Life	: Up to 10 years
Average Weight	: App. 16g
Max. Constant Current	: 1500mA
Max. Pulse Current	: 3500mA
Application	: Smoke Detector, Sensors, Home Security Products, Medical Equipment
Operating Temperature	: -40°C to +60°C
Standards	: UL1642, UL2054, IEC60086-4, UN38.3

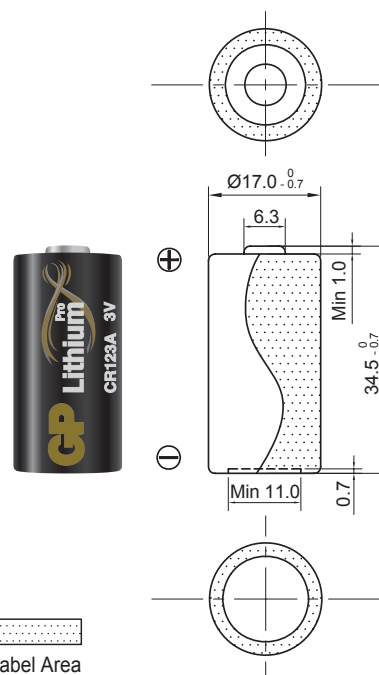

Unit : mm

Cross References:

IEC	GP	Panasonic	Energizer	Duracell
CR17345	CR123A	CR-123A	EL123AP	DL123A

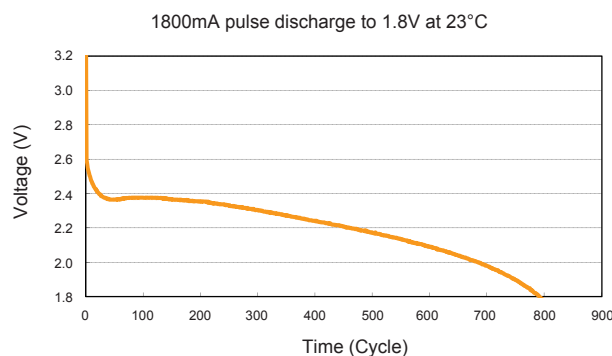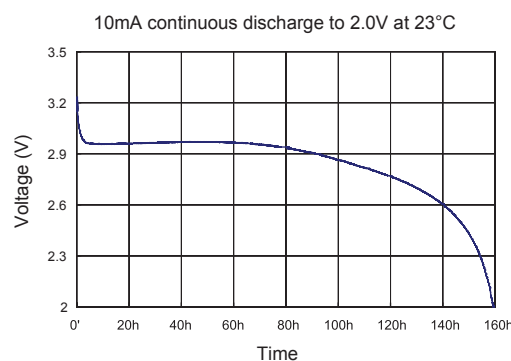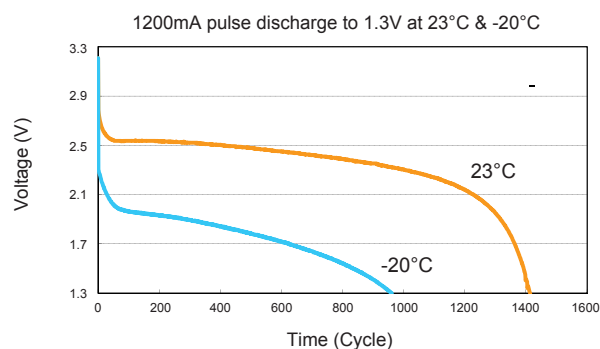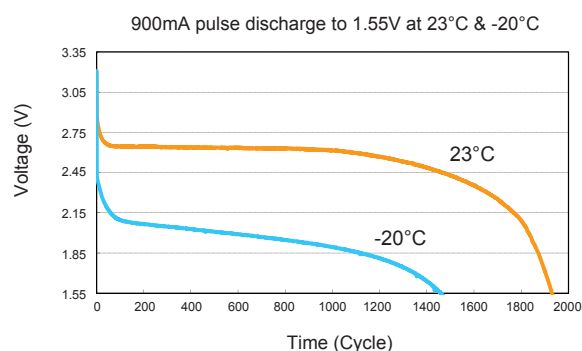

The information (subject to change without prior notice) contained in this document is for reference only and should not be used as a basis for product guarantee or warranty. For applications other than those described here, please consult your nearest GP Sales and Marketing Office or Distributors.

www.gpbatteries.com

Manufacturer reserves the right to alter or amend the design, model and specification without prior notice.
Copyright© GPI International Ltd. - All rights reserved