

IDEAL SHREDCAT 8291

max.
150
sheets

Innovative, compact auto-feed shredder for up to 150 sheets of paper or 8 sheets manually.

← 22 cm →

Level P-4 4 x 10 mm particle cut

Sheet capacity*: 8 / Autofeed: 150



* A4 paper 70 g/m² | 80 g/m²


Technical specifications

Volume	21 l (shred bin)
---------------	------------------

Power	230 V / 50 Hz
--------------	---------------

Motor capacity**	220 Watt
-------------------------	----------

** at maximum sheet capacity

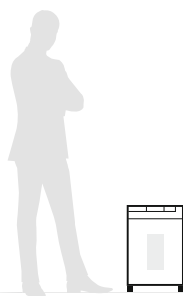

Dimensions	548 x 360 x 235 mm (H x W x D)
-------------------	--------------------------------

Weight	10.1 kg
---------------	---------

Product characteristics

Innovative, space-saving auto-feed system for automatic feeding of paper stacks with up to 150 sheets (A4, 80g/m²). Manual input of up to 8 sheets simultaneously (working width 220 mm). With operating status display via multicolour LED.. Push buttons for forward / stop / reverse. Automatic start and stop via light sensor. Quiet, powerful, and energy-efficient motor. Safe use of the device through a comprehensive safety package. Removable shred bin with a large viewing window as a fill level indicator and automatic shutoff when the container is full. Collection volume of 21 liters. Mobile with lockable casters. Also destroys staples and credit cards.

IDEAL

WWW.IDEAL.DE

IDEAL SHREDCAT 8291

Features



COMPACT AUTO-FEED SYSTEM

Paper stacks of up to 150 sheets can be loaded and automatically shredded.



CONTROL PANEL

Easy operation with push buttons for forward, stop, and reverse. A multicolored LED indicates the operating status.



SHRED BIN

Easy disposal with a pull-out shred bin. Displays „door open“ status.



CASTORS

Four castors (two lockable) ensure mobility and allow flexible use of this shredder.



IDEAL