


DATASHEET

Pneumatic Quick Couple, German Type, Female thread

Dimension drawing

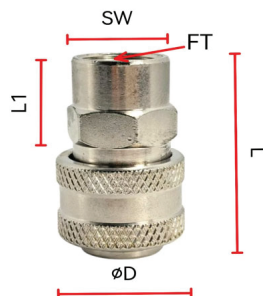

Item No.	Model no.	L	ØD	L1	SW	FT
3594015	TC-TE7-2SF	44.2	26.7	18.9	19.9	1/4" BSP
3594016	TC-TE7-3SF	45.9	26.8	19.8	20.0	3/8" BSP
3594017	TC-TE7-4SF	46.6	26.6	21.4	24.2	1/2" BSP

Measurements for L, ØD, L1 are in mm, SW and FT are non-metric

Technical data

Working pressureMax. 10 bar
 Temperature range-20 to +107 °C
 Material.....Steel
 Air flow.....991 L/min at 6.89 bar inlet with 0.69 bar pressure drop