


DATASHEET

Pneumatic Quick Couple, German Type, Male thread

Dimension drawing

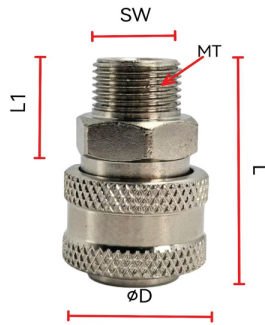

Item No.	Model no.	L	ØD	L1	SW	MT
3594021	TC-TE7-2SM	44.1	26.6	19.2	13.0	1/4" BSP
3594022	TC-TE7-3SM	44.1	26.6	19.2	16.3	3/8" BSP
3594023	TC-TE7-4SM	45.2	26.8	19.5	20.4	1/2" BSP

Measurements for L, ØD, L1 are in mm, SW and MT are non-metric

Technical data

Working pressureMax. 10 bar
 Temperature range-20 to +107 °C
 Material.....Steel
 Air flow.....991 L/min at 6.89 bar inlet with 0.69 bar pressure drop