


DATASHEET

Pneumatic Quick Couple, German Type, Hose Barb

Dimension drawing

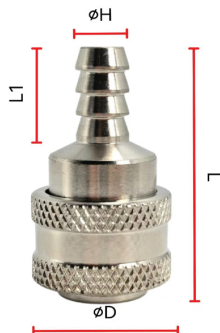

Item No.	Model no.	L	ØD	L1	ØH
3594027	TC-TE7-2SH	52.6	26.3	20.5	6.7
3594028	TC-TE7-3SH	50.8	26.8	17.7	10.1
3594029	TC-TE7-4SH	52.0	26.7	19.0	12.6

Measurements for L, ØD, L1, ØH are in mm

Technical data

Working pressureMax. 10 bar
 Temperature range-20 to +107 °C
 Material.....Steel
 Air flow991 L/min at 6.89 bar inlet with 0.69 bar pressure drop