


DATASHEET

Pneumatic Quick Couple, German Type, Hose Barb

Dimension drawing

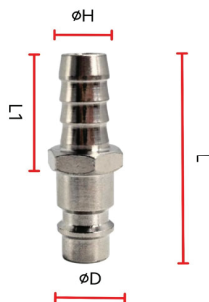

Item No.	Model no.	L	ØD	L1	ØH
3594030	TC-TE7-2PH	45.1	11.9	25.4	6.8
3594031	TC-TE7-3PH	45.0	11.9	25.7	10.0
3594032	TC-TE7-4PH	45.0	11.9	24.8	12.5

Measurements for L, ØD, L1, ØH are in mm

Technical data

Working pressure Max. 10 bar

Temperature range -20 to +107 °C

Material Steel

Air flow 991 L/min at 6.89 bar inlet with 0.69 bar pressure drop