
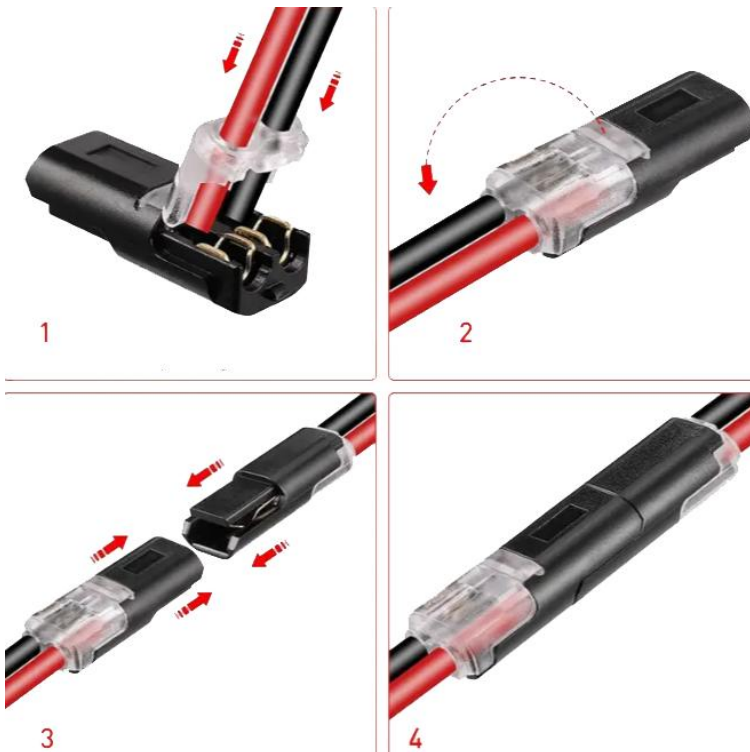


Data Sheet

D3 Quick connection terminal, 30 pcs, 15 sets

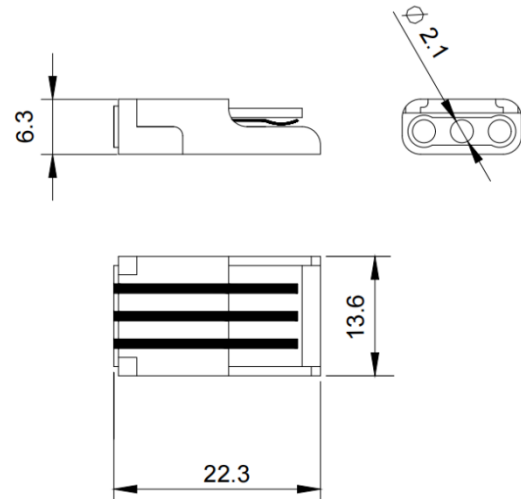

Data Sheet

Technical data

Rated voltage: 12V/24V

Rated current: 9 A

Way: 3

Color: Black

Contact conductor: brass

Minimum cross-sectional area: 0.35 mm²

Maximum cross-sectional area: 0.75 mm²

Maximum outer diameter: 2.1 mm

Working temperature: -20 to +85 °C

Working humidity: 30 - 70% RH non-condensing

Storage temperature: -30 to +100 °C

Storage humidity: 40 - 60% RH non-condensing