


Data Sheet

T2 Quick connection terminal 12PCS

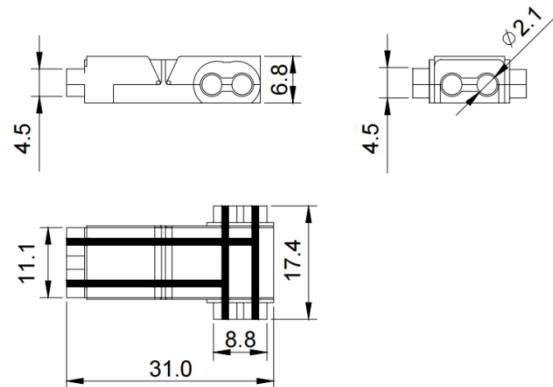

1.



2.



3.



4.

Data Sheet

Technical data

Rated voltage: 36 V

Rated current: 9 A

Way: 2

Color: Black

Contact conductor: brass

Minimum cross-sectional area: 0.5 mm²

Maximum cross-sectional area: 0.75 mm²

Maximum outer diameter: 2.1 mm

Working temperature: -20 to +85 °C

Working humidity: 30 - 70% RH non-condensing

Storage temperature: -30 to +100 °C

Storage humidity: 40 - 60% RH non-condensing