





Data Sheet

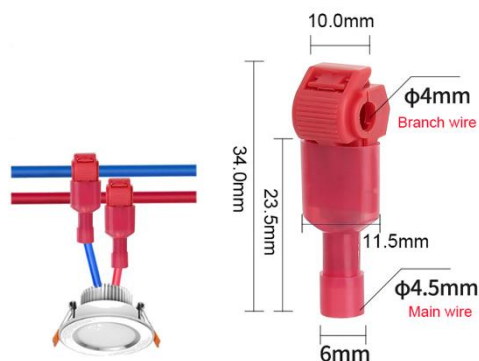



Item no. 3594040 (Red)

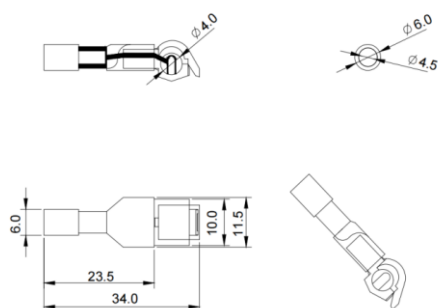

Item no. 3594042 (Blue)

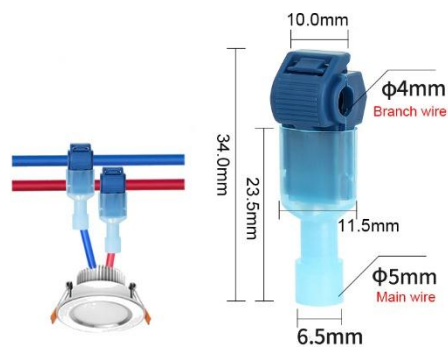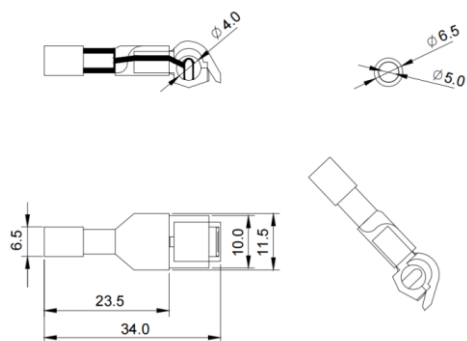


Item no. 3594041 (Yellow)

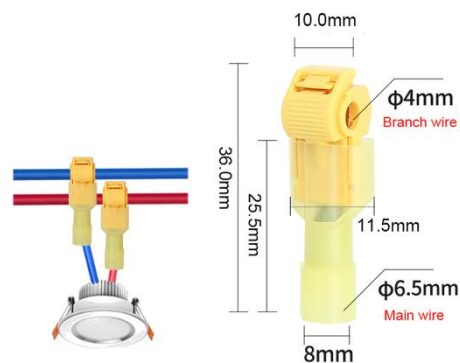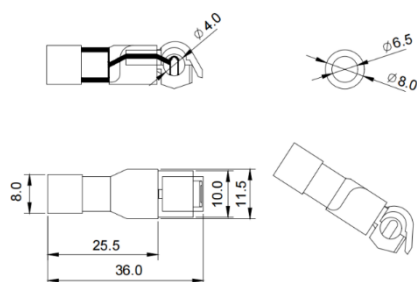

Data Sheet

How to assembly:

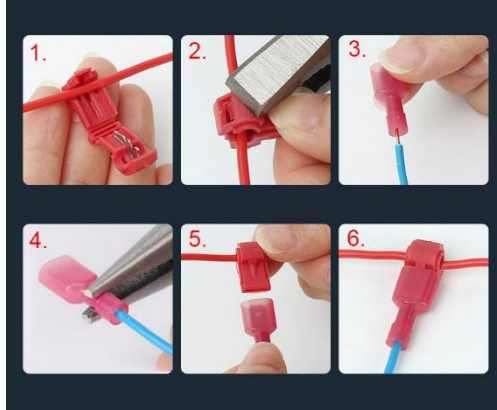

Specification:

Item no.	3594040	3594042	3594041
Color	Red	Blue	Yellow
Rated voltage	12 V/ 24 V		
Rated current	5 A		
Way	1		
Contact conductor	Brass		
Main wire:			
Min. cross-sectional area	0.5 mm ²	1.5 mm ²	2.5 mm ²
Max. cross-sectional area	1.5 mm ²	2.5 mm ²	4.0 mm ²
Max. outer diameter	4.5 mm	5.0 mm	6.5 mm
Stripping length	6.0 mm	6.0 mm	6.0 mm
Branch wire:			
Min. cross-sectional area	0.5 mm ²	1.5 mm ²	2.5 mm ²
Max. cross-sectional area	1.5 mm ²	2.5 mm ²	4.0 mm ²
Max. outer diameter	4.0 mm	4.0 mm	4.0 mm
Operating temperature	-20 to 85 °C		
Storage temperature	-30 to 100 °C		
Operating humidity	30 - 70% RH non-condensing		
Storage humidity	40 - 60% RH non-condensing		